

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190700078

Status:

Active

Overview:

Solderless Terminals

Description:

InsulKrimp™ Ring Tongue Terminal for 14-16 AWG Wire


Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19070
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	InsulKrimp™
Type	Ring
UPC	800753069312
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.047/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/16" (M8)
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Old Part Number	BB-225-56X
Reference - Drawing Numbers	
Sales Drawing	SD-19070-008

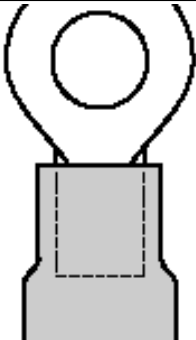

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

19070 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade™	0640010100
Hand Crimp Tool	
Hand Crimp Tool	0640010300
Crimp Head for the	0640050100
AT-200™ Pneumatic	
Hand Tool	
Crimp Head for the	0640050300
AT-200™ Pneumatic	
Hand Tool	

This document was generated on 07/15/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION