


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0082226110
Status: Active
Description: 2.54mm Pitch Round Conductor Flat Cable - 22 AWG (7 x 30) Stranded, Tinned, 10 Circuits, Reel 30.48m Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR61126
UL	E61522
General	
Product Family	Cable
Series	7560
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754370738
Physical	
Cable Length	30.48m
Circuits (Loaded)	10
Insulation	PVC
Net Weight	1595.000/g
Packaging Type	Reel
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	22
Wire/Cable Type	(7x30) Stranded, Tinned
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Old Part Number	7560-10-100B
Reference - Drawing Numbers	
Sales Drawing	SD-7560-001

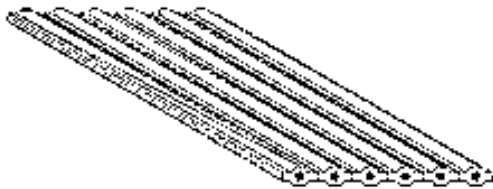

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/21/2016 (20 June 2016) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV
	Green Image Not Relevant

Search Parts in this Series
[7560](#) Series

Use With
[70400](#) C-Grid SL™ IDT Connector
Assembly. [70475](#) SL™ IDT Connector
Assembly. [7720](#) KK® IDT Double Cantilever
Contact

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION