


LED Panel Series

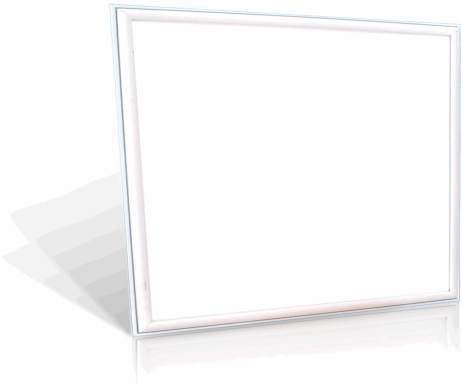

VT-6060

HIGHLIGHTS :

WATTS



45

EQ. WATTS



150

LUMINOUS



3600

BEAM ANGLE



120

| | |
|----------------------------|------------------|
| Item No | : VT-6060 |
| SKU Code | : 60286 |
| Watts | : 45 |
| EQ Watts | : 150 |
| Voltage | : DC:30-42V,50Hz |
| Lumen(lm) | : 3600 |
| Color Temperature | : 2700K |
| Beam Angle | : 120 |
| Commercial type | : SQUARE |
| PF | : >0.9 |
| LED Chip Type | : SMD |
| CRI | : >80 |
| Energy rating label | : A |
| Certification | : CE,EMC,ROHS |
| IP Rating Protection Class | : IP20 |

| | |
|-----------------------|--------------------|
| Body type | : ALUMINUM+PMMA+PS |
| Dimmable | : No |
| Life Time | : >20000 Hours |
| Operation Temperature | : -25 ~50°C |
| EAN code | : 3800230624482 |
| Unit size | : 595x595x14mm |
| Packing details | : 1 |
| Unit cbm | : 0.055859 |

PRODUCT FEATURES

- Compare with incandescent, it can save over 80% electric cost
- Contemporary & Elegant Design
- Higher Light Transmission Rate
- No flickering, No U.V Radiation
- No Lead or Mercury content hence Environment friendly
- Suitable for office and general lighting (Conference Room, Showroom, lobby, cabin, kitchen etc.)
- High quality power driver
- Instant light 100% O s
- Temp -20 to + 45°C

[CLICK HERE FOR OTHER RELATED CERTIFICATES](#) 