

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201095005

Status:


Active

Overview:

Brad® Industrial Ethernet Solutions

Description:

Ultra-Lock® (M12) Ethernet Receptacle, 4 Poles, Female (Straight), D-Coded, , 0.022m (.85") Length

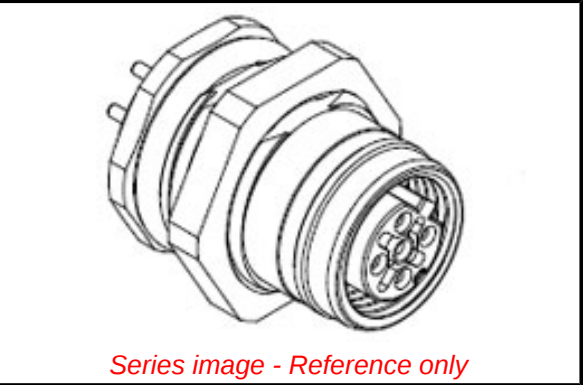

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Receptacles
Series	120109
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad® Industrial Ethernet Solutions
Product Name	Ultra-Lock® (M12)
Type	PCB Mount
UPC	883906436865
Physical	
Coupling Type	Internal Thread
Gender	Female
Keyway	D-coded
Length	0.022m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M16
Orientation	Straight
Panel Mount	N/A
Poles	4
Temperature Range - Operating	-20°C to +75°C
Wire Size AWG	N/A
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V
Material Info	
Engineering Number	ERWD2U70
Reference - Drawing Numbers	
Sales Drawing	SD-120109-004

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

Search Parts in this Series

120109 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION