

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300390297

Status:


Active

Overview:

Brad® Mini-Change® Connectors

Description:

DeviceNet® Trunk Receptacle, 5 Poles, 1/2" - 14 NPT, Male (Straight) to Leads, 0.050m (1.97") Length

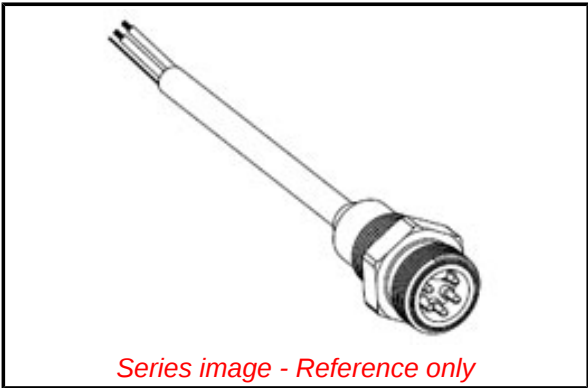

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130039
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad® Mini-Change® Connectors
Product Name	DeviceNet® Trunk
Type	Single Ended (pigtail)
UPC	78678829517
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.50m
Material - Component	Gray Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT
Orientation	Straight
Panel Mount	Front
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	18
Wire/Cable Type	Thick Standard Cable
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	300V AC/DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Old Part Number	DN5100-M005
Reference - Drawing Numbers	
Sales Drawing	SD-130039-001

*DeviceNet is a trademark of Open DeviceNet Vendor Association (ODVA).

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

Search Parts in this Series

130039 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION