


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390382](#)
Status: **Active**
Overview: [Brad® Micro-Change® \(M12\) Connectors](#)
Description: Micro-Change® Terminator, Male Standard with Resistor, 5 Pole

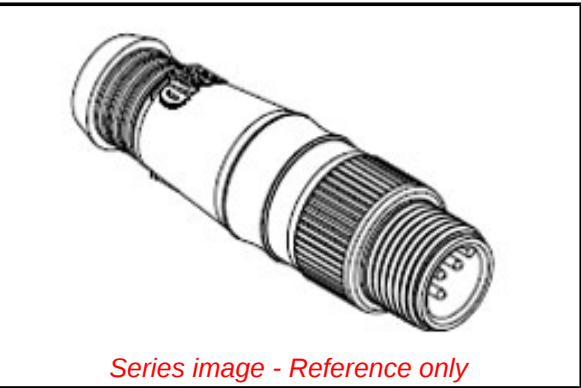

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Field Attachable / Accessories
Series [130039](#)
IP Rating IP67
Overview [Brad® Micro-Change® \(M12\) Connectors](#)
Product Name Micro-Change® (M12)
Type Terminator
UPC 78678830951

Physical
Cable Diameter N/A
Coupling Type External Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway None
Material - Connector Body Polyamide
Material - Contact Copper
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold over Copper
Orientation Straight
Poles 5
Temperature Range - Operating 0°C to +60°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 4.0A
Voltage - Maximum 30V

Material Info
Old Part Number DND100

Reference - Drawing Numbers
Sales Drawing SD-130039-011

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant

Search Parts in this Series
[130039](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION