

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190700070](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp™ Ring Tongue Terminal for 14-16 AWG Wire

Documents:
[3D Model](#) [Product Specification PS-19902-011 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series [19070](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name InsulKrimp™
Type Ring
UPC 800753069237

Physical
Barrel Type Closed
Color - Resin Natural
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 0.678/g
Packaging Type Adhesive Tape on Reel
Stud Size 5-6 (M3-3.5)
Wire Insulation Diameter 4.40mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number BB-223-06XT

Reference - Drawing Numbers
Product Specification PS-19902-009, PS-19902-011
Sales Drawing SD-19070-008

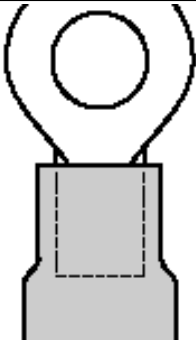

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/21/2016 (20 June
2016)
Halogen-Free
Status
Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
[19070](#) Series

Application Tooling | FAQ
*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	0192880123
Mini-Mac™ Applicator	0638850400

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION