

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190730015
Status: Active
Overview: Solderless Terminals
Description: Avikrimp™ Ring Tongue Terminal for 18 to 22 AWG Wire, Stud Size 8 (M4), Length 22.00mm, Mylar Tape Carrier

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series 19073
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Avikrimp™
Type Ring
UPC 800753075061

Physical
Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.875/g
Packaging Type Adhesive Tape on Reel
Stud Size 8 (M4)
Wire Insulation Diameter 3.60mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number AA-821-08T

Reference - Drawing Numbers
Product Specification PS-19902-011
Sales Drawing SD-19073-002

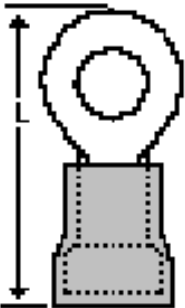

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/21/2016 (20 June
2016)
Halogen-Free
Status
Not Low-Halogen

Need more information on product environmental compliance?
Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
19073 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Mini-Mac™	0638851300
Applicator	
ATP Crimp Dies	0192880023
for the Tape Crimp	
Module and ATP-101	
& 301 Press	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION