


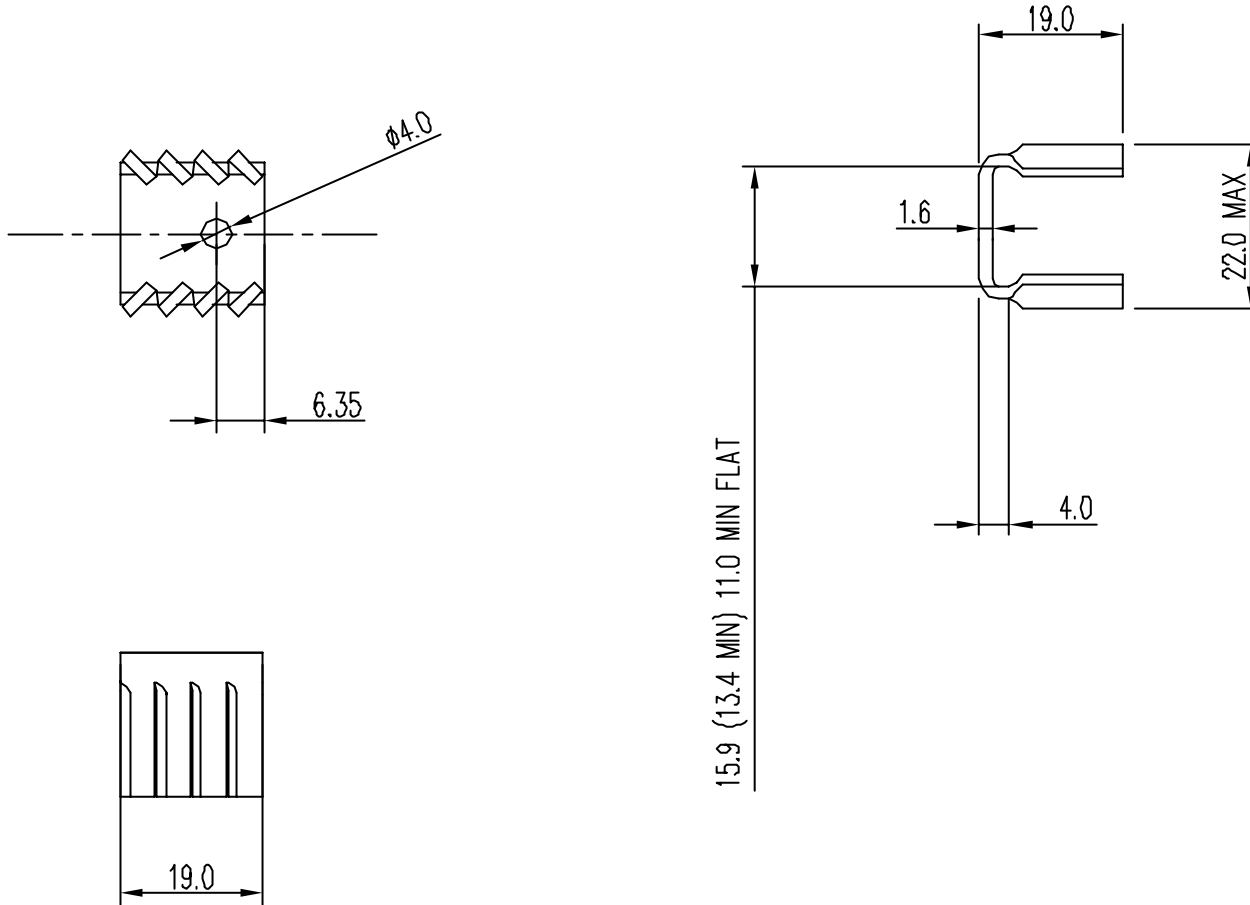

THIS DOCUMENT CONTAINS AAVID THERMALLOY'S INTELLECTUAL PROPERTY WHICH IS SUPPLIED IN CONFIDENCE; IT MUST NOT BE USED FOR ANY PURPOSE OTHER THAN WHICH IT IS SUPPLIED; IT MUST NOT BE REPRODUCED WITHOUT WRITTEN PERMISSION FROM THE OWNERS

# TV-5




**AAVID THERMALLOY**  
EUROPE [www.avidthermalloy.com](http://www.avidthermalloy.com)

Via XIV Aprile, 32  
40067 Castelboe - Bologna ITALY  
Tel. +39 051 784011 Fax +39 051 784028

Cherney Manor  
SWINDON WILTS SN2 2QN UK  
Tel. +44 1793 401400 Fax +44 1793 815368

COMPANY WITH QUALITY SYSTEM CERTIFIED BY LRQA  
ISO 9001:2000

Die n.	MATERIAL 16 SWG AL ALLOY 1200-BS147D				DRAWING n.	437919	
Factor	GENERAL TOLERANCES Extrusion UNI EN 755				Vis. n.		
Perim.	Machining UNI EN 22768				Description:	HTSK- STAMPING	
Area	FINISH BLACK ANODISE				Format	A4	Scale
Weight	0.0035 kg/m				Scale	1:1	1
Notes	Drawn E.De Nardo				By		
	Check	A	14APR06	ORIGINAL (was ZA0779-7)			
		REV	Date	Revision description			