

Category 6A Shielded Keystone Panel Mount Coupler



Category 6A Shielded Keystone Panel Mount Coupler (SGACK2S, SGACK2S-24)

Features


- Designed to fit US industry standard keystone outlets, wall plates and patch panels
- RJ45 complies with FCC part 68 standard
- Jack insertion life > 750 mating cycles
- Operating temperature: -40°C ~ +60°C
- High performance data throughput Category 6A, ANSI/TIA/EIA-568-B.2-10 – can run 10GBASE-T at 100 metres
- Available as part of our innovative Panel Mount and D UNIVERSAL ranges

Packaging

- Standard product is supplied in individual polythene bags. To save time for panel assemblers, SGACK2S-24 is available as a “bulk-pack” of 24 pieces without individual bags.

Specifications

- **Materials**
Housing: Nickel plated zinc alloy
Earthing lug material: Stainless steel SUS304
Contacts: 50µ"/1.27µm gold plated over nickel over phosphor bronze
- **Weight:**
SGACK2S: 17g SGACK2S-24: 410g
- **Dimensions:**
SGACK2S: 29.7 x 17 x 16.1 mm approx. SGACK2S-24: 282 x 70 x 35mm approx.

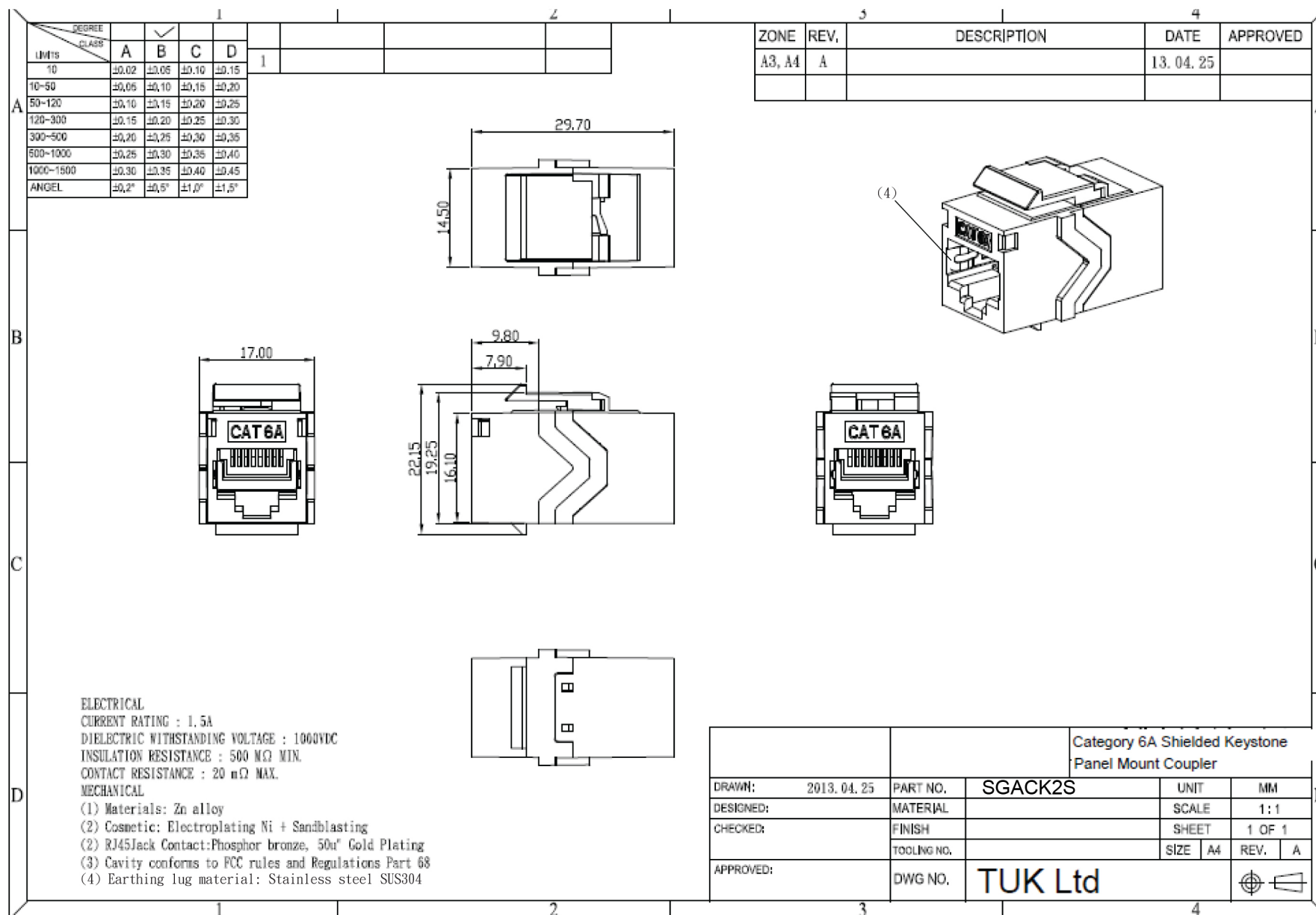

TUK Ltd, Unit 4, Wimbledon Stadium Business Centre, Riverside Road, London, SW17 0BA