


## Sleeving

### PVC Sleeving – On a drum

A commercial grade of PVC sleeving which can be used in many applications.

#### Features and Benefits

- Highly flexible insulation
- Can also be used for identification
- Minimum working temperature -30°C
- Maximum working temperature 85°C
- Specification: BS2848 Type 3, Class 85T
- Colours available: blue, brown, green/yellow
- Other sizes are available on request
- Supplied on a drum

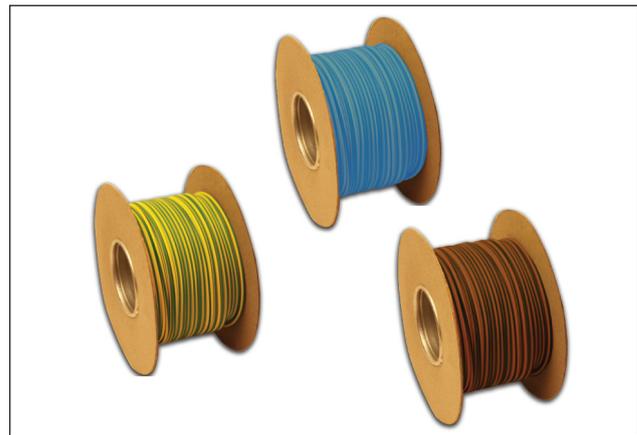

PVC Sleeving on a drum.

TYPE	ID mm	Wall Thickness mm	Colour	Pack Cont.	Article-No.
PVC20BERL	2.0	0.5	Blue	100m drum	172-02092
PVC20BNRL	2.0	0.5	Brown	100m drum	172-02091
PVC20GN-YWRL	2.0	0.5	Green-Yellow	100m drum	172-02088
PVC30BERL	3.0	0.5	Blue	100m drum	172-02094
PVC30BNRL	3.0	0.5	Brown	100m drum	172-02093
PVC30GN-YWRL	3.0	0.5	Green-Yellow	100m drum	172-02089
PVC40BERL	4.0	0.5	Blue	100m drum	172-02096
PVC40BNRL	4.0	0.5	Brown	100m drum	172-02095
PVC40GN-YWRL	4.0	0.5	Green-Yellow	100m drum	172-02090

All dimensions are in mm (nominal) and are subject to technical modification.