


**Bulletin 800F**  
**22.5 mm Push Buttons**  
**Product Selection, Continued**

2-Position Key Operated Selector Switches, Non-Illuminated

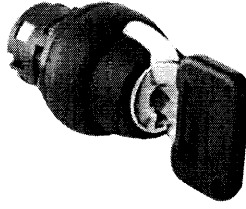

Key Selector Switch  
 Cat. No. 800FP-KM21R

Switching Angle



| Target Table and Operator Position* |   |   |
|-------------------------------------|---|---|
| Contact Type                        |   |   |
| N.O.                                | O | X |
| N.C.                                | X | O |

Note: X = Closed/O = Open

| Key Removal Position | Operator Type | Key Selector Switch Operators |            | Pkg. Quantity |
|----------------------|---------------|-------------------------------|------------|---------------|
|                      |               | Plastic                       | Metal      |               |
|                      |               | Cat. No.                      | Cat. No.   |               |
| Left                 |               | 800FP-KM21                    | 800FM-KM21 | 1             |
| Both                 |               | 800FP-KM23                    | 800FM-KM23 |               |

\* Target table for spring return from left is reversed from what is shown in the table.

**800F** M - KM2 1 -      -     

a                      b                      c                      d                      e

a


| Operator Construction |  |
|-----------------------|--|
| Code                  | Description                              |
| P                     | Round plastic operator (IP66, Type 4/13) |
| M                     | Round metal operator (IP66, Type 4/13)   |

b

| Operator Type |  |  |
|---------------|--|--|
| Code          | Type   |  |
| KM2           | Maintained (60° switching angle)               |  |
| KL2           | Spring return from left (60° switching angle)  |  |
| KR2           | Spring return from right (60° switching angle) |  |

c

| Key Removal Position** |          |  |
|------------------------|----------|--|
| Code                   | Position |  |
| 1                      | Left     |  |
| 2                      | Right    |  |
| 3                      | Both     |  |

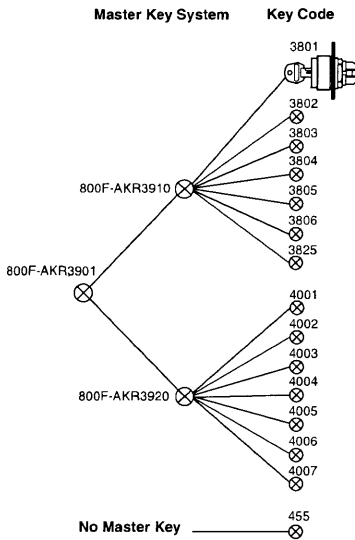

d

| Ronis Key Lock†‡ |                 |
|------------------|-----------------|
| Code             | Key No.         |
| Blank            | 3825 (Standard) |
| R                | 455             |
| 01R              | 3801            |
| 02R              | 3802            |
| 03R              | 3803            |
| 04R              | 3804            |
| 05R              | 3805            |
| 06R              | 3806            |
| 27R              | 4001            |
| 28R              | 4002            |
| 29R              | 4003            |
| 30R              | 4004            |
| 31R              | 4005            |
| 32R              | 4006            |
| 33R              | 4007            |

e

| Packaging |                |
|-----------|----------------|
| Code      | Description    |
| Blank     | 1 per package  |
| BP        | 10 per package |

\*\* Key removal in maintained positions only.

† Keyed operators are IP66, Type 4/13.

‡ Not intended for high security applications. Interoperability is possible with certain key/cylinder lock combinations. Consult your local Allen-Bradley distributor for interoperability information.

‡ For Ronis replacement keys, see Accessories, page 53.