

Product Description:

The new fixed and adjustable E5™ and established E8™ fixed and adjustable fire rated downlights set new levels in performance. Featuring the sparkling low glare multifaceted EnFiniti™ lens and delivering up to 380lm from 4.5W version and 595lm from 8W. The E5™ and E8™ are packed with features and benefits which allow for a quick and cost effective installation while still providing users with optimum performance and energy saving LED technology. Tested in 30, 60 and 90-minute fire rated ceilings.

Product Image:




Product Features:

- EnFiniti™ edge-to-edge multifaceted polycarbonate lens for low glare and halogen like appearance
- Wide 60° beam angle delivers increased light distribution
- Fibre based insulation coverable - up to 250mm
- Integrated driver with push fit loop in/out terminals suitable for use with solid or stranded cable for easy installation
- Super slim interchangeable bezels for fixed version provide a high end sleek finish. Bezel included with adjustable version.
- Community Design Registrations for E5™ and E8™
- BS EN 1365-2:2014 (Fire resistance)
- BS EN ISO 10140-2: 2010 & BS EN ISO 10140-3: 2010 + A1: 2015 (Acoustics)
- BS EN 13141-1:2004 (Air leakage) - excluding adjustable version
- 3 year warranty

E5 Fixed 4.5W Dimmable IP65 Fire Rated LED Downlight

Line Drawing Image

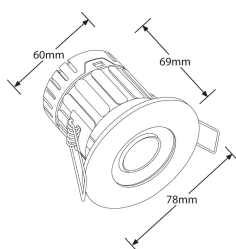

Product Specs:

| | | | |
|------------------------|-------------|-----------------------|---------|
| Technology | LED | Number of LEDs | 6 |
| Luminaire Distribution | Direct | Lifetime L70 (hrs) | 25000 |
| Input Voltage | 220~240V AC | Input Frequency | 50/60HZ |
| Surge Protection (kV) | 0.5 | Power Factor | 0.7 |
| Dimmable | Yes | IP Rating | IP65 |
| Fire Protection | Yes | Acoustic Rated | Yes |
| Optic Material | PC | Height (mm) | 68.5 |
| Cutout Diameter (mm) | 60 | Overall Diameter (mm) | 78 |
| Overall Height (mm) | 68.5 | Recess Depth (mm) | 69 |

SKU Table and Ordering

| Cat No.(SKU Code) | Wattage | Lumens | Lumens/Watt | Colour | Ra | Beam Angle | SDCM |
|-------------------|---------|--------|-------------|--------|----|------------|------|
| EN-DE5/30 | 4.5W | 355lm | 78.89 | 3000K | 80 | 60° | 6 |
| EN-DE5/40 | 4.5W | 380lm | 84.44 | 4000K | 80 | 60° | 6 |

Compliance & Approvals:



Warranty

Please contact Aurora for specifics concerning warranty on this product. The warranty is invalid in the case of improper use, installation, tampering, and removal of the Q.C. date label; installation in an improper working environment or installation not according to the current edition of the National Electric Code. Should this product fail during the warranty period it will be replaced free of charge, subject to the correct installation of the original product and subsequent return of the faulty unit. Aurora does not accept responsibility for any installation costs associated with the replacement of this product and Aurora reserves the right to alter specifications without prior notice.

UK Enlite Sales

16 Alban Park Hatfield Road St. Albans
AL4 0JJ

United Kingdom

Tel : +44 (0) 1727 83 66 11

Fax : +44 (0) 1727 83 66 22

UK Enlite Distribution

Apex Park 6 Little Burrow Welwyn
Garden City AL7 4SW

United Kingdom

Tel : +44 (0) 1707 35 18 20

Fax : +44 (0) 1727 35 18 21