

Product Description:

The Enlite range of Slim-Fit™ low profile downlights are engineered to deliver superior light output and uniformity utilising the latest edge-lit LED technology. At only 25mm deep including bracket, they are an ideal solution where ceiling voids are limited but high lumen output is required. 3 year warranty


Product Image:



Product Features:

18W IP44 Round Low Profile LED Downlight

Line Drawing Image

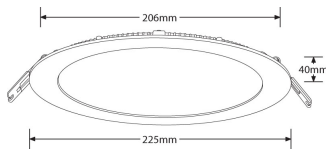

Product Specs:

Technology	LED	Number of LEDs	90
Lifetime L70 (hrs)	25000	Input Voltage	100~240V AC
Input Frequency	50/60HZ	Surge Protection (kV)	1.5
Power Factor	0.9	Dimmable	No
IP Rating	IP44	Operating Temp. (Max) °C	40
Cutout Diameter (mm)	206	Overall Diameter (mm)	225
Overall Height (mm)	25	Recess Depth (mm)	40

SKU Table and Ordering

Cat No.(SKU Code)	Wattage	Lumens	Lumens/Watt	Colour	Ra	Beam Angle	SDCM
EN-PL18B/30	18W	1100lm	61.11	3000K	80	110°	6
EN-PL18B/40	18W	1200lm	66.67	4000K	80	110°	6
EN-PL18B/65	18W	1300lm	72.22	6500K	80	110°	6

Warranty

Please contact Aurora for specifics concerning warranty on this product. The warranty is invalid in the case of improper use, installation, tampering, and removal of the Q.C. date label; installation in an improper working environment or installation not according to the current edition of the National Electric Code. Should this product fail during the warranty period it will be replaced free of charge, subject to the correct installation of the original product and subsequent return of the faulty unit. Aurora does not accept responsibility for any installation costs associated with the replacement of this product and Aurora reserves the right to alter specifications without prior notice.

UK Enlite Sales

16 Alban Park Hatfield Road St. Albans
AL4 0JJ

United Kingdom

Tel : +44 (0) 1727 83 66 11

Fax : +44 (0) 1727 83 66 22

UK Enlite Distribution

Apex Park 6 Little Burrow Welwyn
Garden City AL7 4SW

United Kingdom

Tel : +44 (0) 1707 35 18 20

Fax : +44 (0) 1727 35 18 21