

LUMINAIRES - FIRE RATED DOWNLIGHTING

AU-MPRO2

Product Description:


IP65, Adjustable, integrated, fire rated 7W LED downlight with unique convertible design to fit ceiling voids as shallow as 47mm. Incorporated miniaturised NanoDrive™ power supply. Available in 2700K, 3000K and 4000K, mPro™ delivers up to 94lm/W making it the most efficient fire rated downlight on the market. Available in White, Matt White, Polished Chrome and Satin Nickel. Fitted with 60° lens. Insulation cover and FastRFix™ rapid install system connector included. Rated to 30, 60 and 90 minute fire ceilings. Class 2 rated with floating earth terminal. Complies with BS EN 1365-2: 2014 (fire resistance), BS EN ISO 10140-2: 2010 & BS EN ISO 10140-3: 2010 + A1: 2015 (acoustics), BS EN 13141-1:2004 (Air leakage).

5 year extended warranty - register at auroralighting.com/warranty


Product Image:



Line Drawing

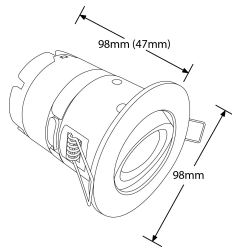

Polar Curve

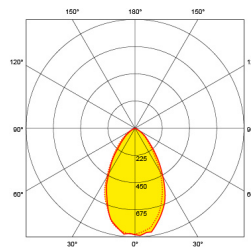

Product Specs:

Technology	LED	Positional Adjustment	Adjustable
Number of LEDs	9	Luminaire Distribution	Direct
Lifetime L70 (hrs)	40000	Input Voltage	220~240V AC
Input Frequency	50/60HZ	Dimmable	Yes
IP Rating	IP65	Fire Protection	Yes
Acoustic Rated	Yes	Operating Temp	25°C
Optic Material	PC	Power Factor	0.85
Overall Diameter (mm)	98	Overall Height (mm)	103
Recess Depth (mm)	100	Cutout Diameter (mm)	85
Weight (Kg)	0.546		

SKU Table and Ordering:

Cat No.(SKU Code)	Wattage	Beam Angle	Lumens	Lumens/Watt	Colour	Finish Colour
AU-MPRO2PC/40	7W	60°	660lm	94.29	4000K	Polished Chrome
AU-MPRO2PC/30	7W	60°	630lm	90	3000K	Polished Chrome
AU-MPRO2PC/27	7W	60°	600lm	85.71	2700K	Polished Chrome
AU-MPRO2MW/40	7W	60°	660lm	94.29	4000K	Matt White
AU-MPRO2MW/30	7W	60°	630lm	90	3000K	Matt White
AU-MPRO2MW/27	7W	60°	600lm	85.71	2700K	Matt White
AU-MPRO2W/40	7W	60°	660lm	94.29	4000K	White
AU-MPRO2W/30	7W	60°	630lm	90	3000K	White
AU-MPRO2W/27	7W	60°	600lm	85.71	2700K	White
AU-MPRO2SN/40	7W	60°	660lm	94.29	4000K	Satin Nickel
AU-MPRO2SN/30	7W	60°	630lm	90	3000K	Satin Nickel
AU-MPRO2SN/27	7W	60°	600lm	85.71	2700K	Satin Nickel

Compliance & Approvals:



Warranty:

Please contact Aurora for specifics concerning warranty on this product. The warranty is invalid in the case of improper use, installation, tampering, and removal of the Q.C. date label; installation in an improper working environment or installation not according to the current edition of the National Electric Code. Should this product fail during the warranty period it will be replaced free of charge, subject to the correct installation of the original product and subsequent return of the faulty unit. Aurora does not accept responsibility for any installation costs associated with the replacement of this product and Aurora reserves the right to alter specifications without prior notice.

UK Sales

16 Alban Park Hatfield Road St. Albans
AL4 0JJ
United Kingdom
Tel : +44 (0) 1727 83 66 11
Fax : +44 (0) 1727 83 66 22

UK Distribution

Apex Park 6 Little Burrow Welwyn
Garden City AL7 4SW
United Kingdom
Tel : +44 (0) 1707 35 18 20
Fax : +44 (0) 1727 35 18 21