

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009503081

Status:

Active

Overview:

KK® Interconnect System - Molex

Description:

KK® 3.96mm Crimp Terminal Housing, Friction Ramp, 8 Circuits

Documents:


3D Model

Packaging Specification PK-2139-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
Overview	KK® Interconnect System - Molex
Product Name	KK® 396
UPC	800753614062
Physical	
Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.064/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	See Product Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	2139-8A
Reference - Drawing Numbers	
Packaging Specification	PK-2139-001
Sales Drawing	SD-2139

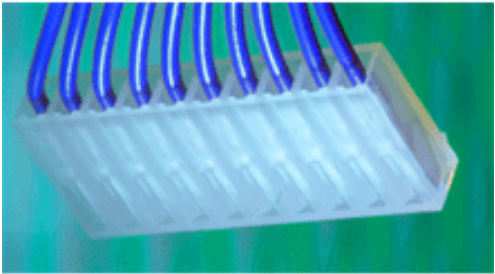

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/21/2016 (20 June

2016)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

2139 Series

Mates With

KK® 396 Headers: [41771](#) , [41772](#) ,

[41791](#) , [41792](#) , [42491](#) , [42492](#) , KK® 396

Breakaway Headers: [41661](#) , [41662](#) , [41671](#)

, [41672](#)

Use With

[2478](#) Crimp Terminals for 18-24 AWG, [2578](#)

Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION