

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0901420006
Status: Active
Overview: C-Grid III™
Description: 2.54mm Pitch C-Grid III™ Crimp Housing Dual Row, 6 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E29179

General
Product Family Crimp Housings
Series 90142
Application Signal, Wire-to-Board
MolexKits Yes
Overview C-Grid III™
Product Name C-Grid III™
UPC 800753659049


Physical
Breakaway No
Circuits (maximum) 6
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin PPO
Net Weight 0.420/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Pitch - Termination Interface 2.54mm
Polarized to Mating Part Yes
Ports 0
Stackable No
Temperature Range - Operating -55°C to +105°C

Electrical
Current - Maximum per Contact 3.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification PS-99020-0001-001
Sales Drawing SD-90142

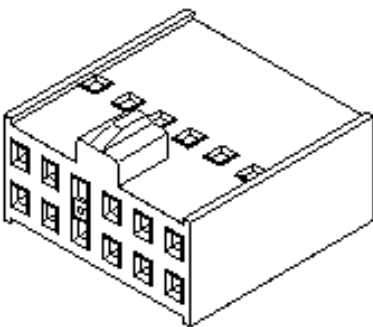

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/21/2016 (20 June
2016)
Halogen-Free
Status
Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[90142](#) Series

Mates With
C-Grid III™ Header, Dual Row [90122](#) ,
[90130](#) , [90131](#)

Use With
C-Grid III™ Crimp Terminal [90119](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION