

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0874210000

Status:


Active

Overview:

Pico-SPOX™ Wire-to-Board Connector System

Description:

1.50mm Pico-SPOX™ Crimp Terminal, Female, Tin(Sn), 24-30 AWG, Reel

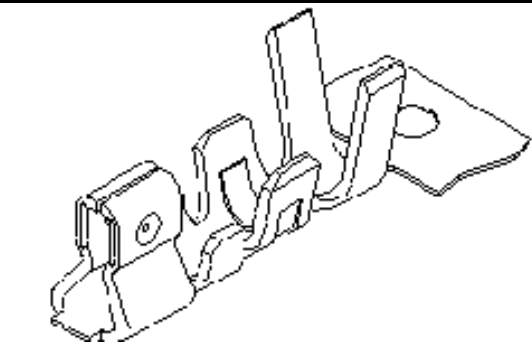

Series image - Reference only

- Documents:
- 3D Model

Packaging Specification SPK-87421-001-001 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-87437-001-001 (PDF)

Product Literature (PDF)

General	
Product Family	Crimp Terminals
Series	87421
Application	Signal
Crimp Quality Equipment	Yes
MolexKits	Yes
Overview	Pico-SPOX™ Wire-to-Board Connector System
Product Literature Order No	USA-235
Product Name	Pico-SPOX™
UPC	800753542686
Physical	
Durability (mating cycles max)	10
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	19.000/mg
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.15mm max.
Wire Size AWG	24, 26, 28, 30
Wire Size mm²	N/A
Electrical	
Current - Maximum per Contact	2.5A
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-87421-001-001
Product Specification	PS-87437-001-001
Sales Drawing	SD-87421-0000

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC

China RoHS

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
87421 Series

Use With
87439 Pico-SPOX™ Wire-to-Board Housing

Application Tooling | FAQ
Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.

Global	
Description	Product #
Extraction Tool	0638132700
Hand Crimp Tool for 1.50mm (.059") Pico-SPOX™ Crimp Terminals	0638259700

FineAdjust Applicator0639014200
for 1.50mm Female
Crimp Terminal,
24-30 AWG Wire
T2 Terminator for 0639114200
1.50mm Female
Crimp Terminal

Japan	
Description	Product #
Applicator for M211A Bench Press, 26 AWG Wire	0572943000

This document was generated on 11/18/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION