


Battery module **PVAF 24/3,2Ah**

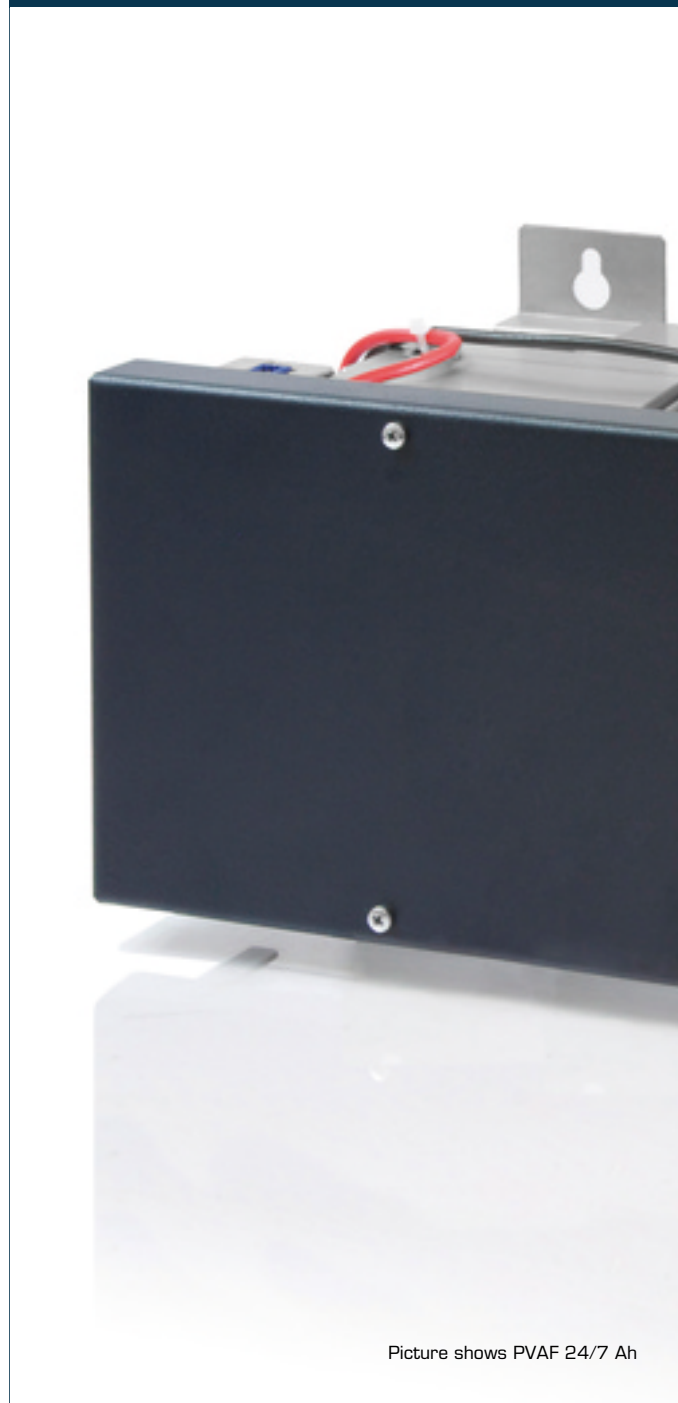

Picture shows PVAF 24/7 Ah

Advantages

Automatic detection of battery modules at UPS control unit

Reliable early warning signal when battery life expectancy is declining


Extended life expectancy through temperature controlled battery management

Service-friendly spring-loaded connector system

Applications

Battery module for building a secure 24 Vdc power supply in case of power failure.

Approvals

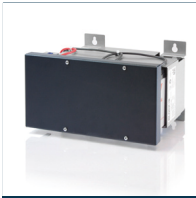

Battery module PVAF 24/3,2Ah

Type		PVAF 24/3,2Ah
Electrical data	Input	
	Input rated voltage	24 Vdc
	Rated capacity	3.2 Ah
	Output	
	Output rated voltage	24 Vdc
	Output rated current	max. 20 A
	Internal fuse	25 A (slow blow)
	Parallel connection	Yes
	Environment	
	Ambient temperature	-10 °C to +40 °C
	Storage temperature	-20 °C to +40 °C
	Service life	5 years at 20 °C
	Latest commissioning (only accumulators)	6 months at 30 - 40 °C
	Safety and protection	
	Protection index	IP 20
Order numbers		
Order Number	PVAF 24/3,2Ah	

Type		PVAF 24/3,2Ah
Mechanical data	Terminal and mounting	
	Terminals input / output (spring clamp terminal, pluggable)	max. 2.5 mm ²
	Terminals temperature measurement, (spring clamp terminal, pluggable)	max. 2.5 mm ²
	Fixing method	DIN Rail system TH 35, screwed mounting
Measures and weights		
	Weight	3,91 kg

