
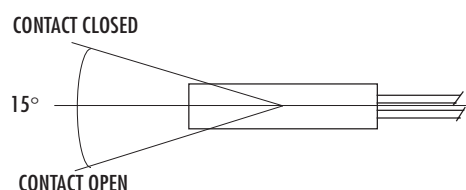


Comus Group of Companies

PRODUCT DATA SHEET

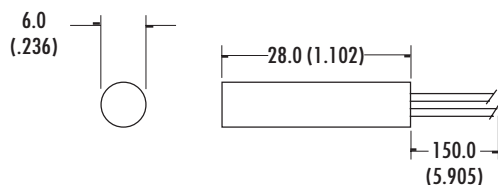

SPECIFICATION

CONTACT FORM / STYLE		-
SWITCHING VOLTAGE	Max. Vac RMS	60 Vac/dc
SWITCHING CURRENT	Max. A	0.1
SWITCHING CAPACITY	Max. VA	3
DIFFERENTIAL ANGLE	Deg. ° Max.	15°
CONTACT RESISTANCE	Max. Ω	100
OPERATING TEMPERATURE	Deg. °C	-37° +100°
STORAGE TEMPERATURE	Deg. °C	-40° +125°
CASE MATERIAL		Polypropylene
CABLE / TERMINATION		2 x round 0.14 ² PVC covered and insulated

TILT SWITCH MODULE - Mercury Free

 PART NUMBER
CW60S/15

Rev. No.	Revision Note	Date	Signature
A	Web Site 1999	1-5-99	RG

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and details of our full design and manufacturing service. All products are supplied to our standard conditions of sale otherwise agreed in writing.