

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192130009

Status:

Active

Overview:

Wire Pins

Description:

Avikrimp™ Wire Pin Terminal for 22-18 AWG Wire, Loose in bag

Documents:

3D Model


Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                              |                                    |
|------------------------------|------------------------------------|
| Agency Certification         |                                    |
| CSA                          | LR18689                            |
| UL                           | E32244                             |
| General                      |                                    |
| Product Family               | Crimp Terminals                    |
| Series                       | 19213                              |
| Application                  | Power                              |
| Comments                     | Pin Length 9.91mm                  |
| Crimp Quality Equipment      | Yes                                |
| MolexKits                    | Yes                                |
| Overview                     | Wire Pins                          |
| Packaging Alternative        | 19213-0010 (Adhesive Tape on Reel) |
| Product Name                 | Wire Pin                           |
| UPC                          | 800753053496                       |
| Physical                     |                                    |
| Flammability                 | 94V-2                              |
| Gender                       | Male                               |
| Material - Metal             | Copper                             |
| Material - Plating Mating    | Tin                                |
| Net Weight                   | 0.845/g                            |
| Packaging Type               | Bag                                |
| Plating min - Mating         | 1.016µm                            |
| Termination Interface: Style | Crimp or Compression               |
| Wire Insulation Diameter     | 6.35mm max.                        |
| Wire Size AWG                | 18, 19, 20, 22                     |
| Wire Size mm²                | N/A                                |
| Material Info                |                                    |
| Engineering Number           | WP-8218                            |
| Reference - Drawing Numbers  |                                    |
| Product Specification        | PS-19902-011-001, PS-19902-013-001 |
| Sales Drawing                | SD-19213-002                       |

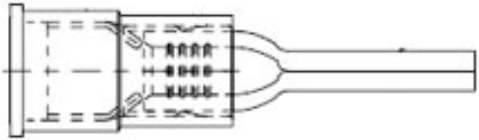

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

19213 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

| Description                                    | Product #  |
|------------------------------------------------|------------|
| PremiumGrade™ Hand Crimp Tool                  | 0640010100 |
| Crimp Head for the AT-200™ Pneumatic Hand Tool | 0640050100 |

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**