

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190030064

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

InsulKrimp™ Quick Disconnect, Female, for 24-26 (0.20-0.12mm²), Box, Tab 4.75 x 0.51mm

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

Drawing (PDF)

Product Specification PS-19902-013-001 (PDF)

Product Specification PS-19902-008-001 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Quick Disconnects

Series

19003

Comments

Funnel Entry

Crimp Quality Equipment

Yes

Insulated

Fully

Overview

Standard Quick-Disconnect Terminals

Product Name

InsulKrimp™

Type

Quick Disconnect

UPC

800753029491

Physical

Barrel Type

Closed

Color - Resin

Yellow

Gender

Female

Glow-Wire Compliant

Yes

Insulation

Nylon (PA)

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Net Weight

0.725/g

Orientation

Straight

Packaging Type

Bag

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Polarized to Mating Part

No

Tab Thickness

0.51mm

Tab Width

4.75mm

Temperature Range - Operating

-65°C to +105°C

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

1.90mm max.

Wire Size AWG

24, 26

Electrical

Voltage - Maximum

600V

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info


Engineering Number

M-2210

Reference - Drawing Numbers

Product Specification

PS-19902-008-001, PS-19902-011-001, PS-19902-013-001

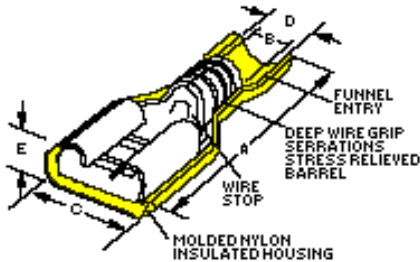

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -ED/79/2015 (17 December 2015)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19003 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool

0640015200

Crimp Head for the AT-200™ Pneumatic Hand Tool

0640055200

This document was generated on 11/17/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION