

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050375063

Status:

Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

2.50mm Pitch SPOX™ Wire-to-Board Crimp Housing, Friction Lock, 6 Circuits

Documents:

3D Model

Packaging Specification SPK-5264-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-5264-001-001 (PDF)

Agency Certification

UL

E29179

General

Product Family

Crimp Housings

Series

5264

Application

Signal, Wire-to-Board

MolexKits

Yes

Overview

SPOX™ Wire-to-Board Connectors

Product Name

SPOX™

UPC

800753578371

Physical

Circuits (maximum)

6

Flammability

94V-0

Gender

Female

Glow-Wire Compliant

No

Net Weight

330.500/mg

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

2.50mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

-40°C to +105°C

Material Info

Engineering Number

5264-06

Reference - Drawing Numbers

Packaging Specification


SPK-5264-001-001

Product Specification

PS-5264-001-001

Sales Drawing

SD-5264-N

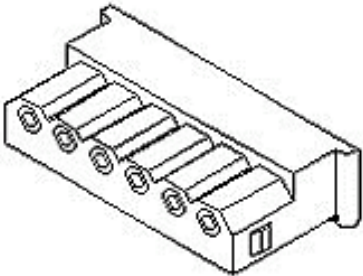

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/21/2016 (20 June

2016)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

5264 Series

Mates With

5267 vertical shrouded PCB header, 5268

right angle shrouded PCB header

Use With

5263

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION