




## Product Sheet

Part Number:

**CDSF 42**

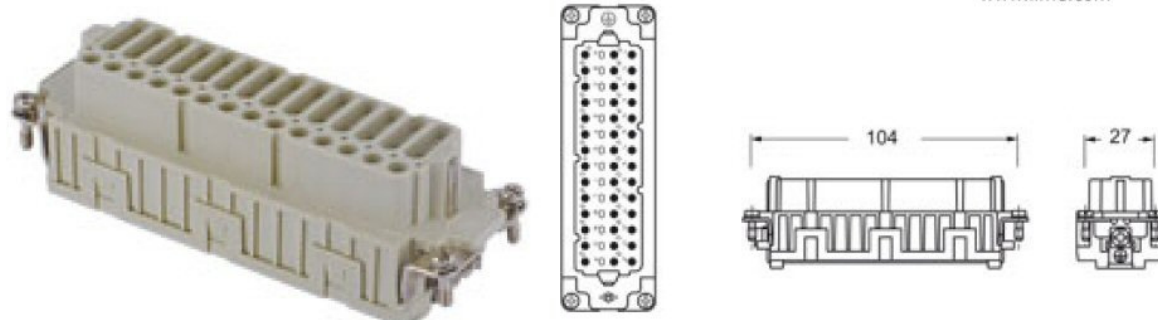

Family	inserts
Version	spring terminal connections
Series	CDS
Product type	with female contacts
Model	female insert
Reference standard	EN 61984 (2001-11)
Contact type	silver plated
No. of poles	42 poles + 
Voltage (V)	400V
Current (A)	10A (A.C./D.C.)
Wire section	0,14mm <sup>2</sup> - 2,5mm <sup>2</sup>
Awg size	26 - 14
Quality mark	
IP degree of protection	IP20 degree of protection without enclosure; IP65, IP66, IP67, IP68 (EN 60529) and IP69K (DIN 40050 - 9) with enclosure
Fixing centre distance	size "104.27"
Impulse withstand voltage	6kV
Pollution degree	3

The information and the dimensions contained are not binding and may be changed without prior notice.  
The drawing's dimensions are in mm.