

Classic filament LED Lamps

CLA LEDBulb D 7-50W ST64 E27 820 GOLD

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light bulbs.

Product data

| General Information | |
|--|------------|
| Cap base | E27 [E27] |
| Bulb shape | ST64 |
| Nominal lifetime (nom.) | 15000 h |
| Switching cycle | 20000X |
| Technical type | 7-50W |
| Light Technical | |
| Luminous flux (nom.) | 630 lm |
| Luminous flux (rated) (nom.) | 630 lm |
| Colour designation | Flame |
| Correlated colour temperature (nom.) | 2000 K |
| Luminous efficacy (rated) (nom.) | 90.00 lm/W |
| Colour consistency | <6 |
| Color rendering index (nom.) | 80 |
| LLMF at end of nominal lifetime (nom.) | 70 % |
| Operating and Electrical | |
| Input frequency | 50-60 Hz |


| Power (Rated) (Nom) | 7 W |
|----------------------------------|-----------------|
| Lamp current (nom.) | 40 mA |
| Wattage equivalent | 50 W |
| Starting time (nom.) | 0.5 s |
| Warm-up time to 60% light (nom.) | 0.5 s |
| Power factor (nom.) | 0.7 |
| Voltage (Nom) | 220-240 V |
| Controls and Dimming | |
| Dimmable | Yes |
| Approval and Application | |
| Energy-saving product | Yes |
| Suitable for accent lighting | No |
| Energy efficiency label (EEL) | A+ |
| Energy Consumption kWh/1000 h | 7 kWh |
| Product Data | |
| Full product code | 871869657573400 |

Classic filament LED Lamps

| | |
|---------------------------------|---------------------------------------|
| Order product name | CLA LEDBulb D 7-50W ST64 E27 820 GOLD |
| EAN/UPC – product | 8718696575734 |
| Order code | 57573400 |
| Numerator – quantity per pack | 1 |
| Numerator – packs per outer box | 6 |

| | |
|---------------------|--------------|
| Material no. (12NC) | 929001228902 |
| Net weight (piece) | 0.060 kg |

Dimensional drawing

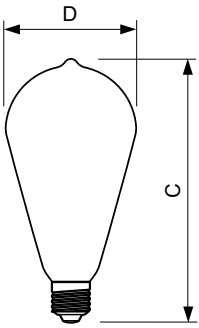

filament 7W-60W 620lm NAD 2200K B22D

| Product | D | C |
|---------------------------------------|-------|--------|
| CLA LEDBulb D 7-50W ST64 E27 820 GOLD | 64 mm | 148 mm |

Photometric data

General Uniform Lighting

