



# SceneSwitch LED Lamps

## LED Scene Switch 60W A60 B22 WW-CW FR ND 1BC/4

Some situations call for cool light, others benefit from the ambiance of a warm cosy glow. With Philips SceneSwitch LED lamps, you can have different light settings from just one bulb, candle or spot. And you don't need a dimmer! Optimise your lighting for relaxing, hobbies, recreation or working. Simply at the flick of a switch. And that's your existing switch! No extra installation is required.

### Product data


| General Information                     |                 |
|-----------------------------------------|-----------------|
| Cap base                                | B22 [ B22]      |
| Bulb shape                              | A60 [ A 60mm]   |
| Nominal lifetime (nom.)                 | 15000 h         |
| Switching cycle                         | 100000X         |
| Technical type                          | 9.5-60W         |
| Technical Type Setting(s)               | 9.5-60 W        |
| Light Technical                         |                 |
| Luminous flux (nom.)                    | 806 lm          |
| Luminous flux (rated) (nom.)            | 806 lm          |
| Colour designation                      | Warm white (WW) |
| Correlated Color Temperature Setting(s) | 2700/4000 K     |
| Luminous efficacy (rated) (nom.)        | 84.84 lm/W      |
| Colour consistency                      | <6              |
| Color rendering index (nom.)            | 80              |

|                                        |           |      |
|----------------------------------------|-----------|------|
| LLMF at end of nominal lifetime (nom.) |           | 70 % |
|                                        |           |      |
| Operating and Electrical               |           |      |
| Input frequency                        | 50-60 Hz  |      |
| Power (Rated) (Nom)                    | 9.5 W     |      |
| Lamp current (nom.)                    | 100 mA    |      |
| Wattage equivalent                     | 60 W      |      |
| Starting time (nom.)                   | 0.5 s     |      |
| Warm-up time to 60% light (nom.)       | 0.5 s     |      |
| Power factor (nom.)                    | 0.5       |      |
| Voltage (Nom)                          | 220-240 V |      |
|                                        |           |      |
| Controls and Dimming                   |           |      |
| Dimmable                               | No        |      |

SceneSwitch LED Lamps

|                               |                 |
|-------------------------------|-----------------|
| Mechanical and Housing        |                 |
| Bulb finish                   | Frosted (FR)    |
| Approval and Application      |                 |
| Energy-saving product         | Yes             |
| Suitable for accent lighting  | No              |
| Energy efficiency label (EEL) | A+              |
| Energy Consumption kWh/1000 h | 9.5 kWh         |
| Product Data                  |                 |
| Full product code             | 871869659841200 |

Dimensional drawing

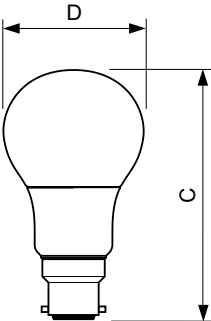

SSW EMEA Color\_9.5W 827-40 800lm B22 ND

|                                 |                                                |
|---------------------------------|------------------------------------------------|
| Order product name              | LED Scene Switch 60W A60 B22 WW-CW FR ND 1BC/4 |
| EAN/UPC – product               | 8718696598412                                  |
| Order code                      | 59841200                                       |
| Numerator – quantity per pack   | 1                                              |
| Numerator – packs per outer box | 4                                              |
| Material no. (12NC)             | 929001264201                                   |
| Net weight (piece)              | 0.065 kg                                       |

| Product                                        | D     | C      |
|------------------------------------------------|-------|--------|
| LED Scene Switch 60W A60 B22 WW-CW FR ND 1BC/4 | 61 mm | 111 mm |

## Photometric data

## General Uniform Lighting

