



MASTER LEDcandle DiamondSpark

MASTER LEDcandle DT 6-40W E27 B38 CL

Delivering incandescent-like sparkling light effects, MASTER LEDcandle bulbs are ideal for general and decorative lighting in the hospitality industry, as well as in home environments. The dimmable MASTER LEDcandles drive further efficiencies, while helping to create the desired atmosphere. Mounted in full view in chandeliers, wall scones or modern luminaires, the clear or frosted glass bulbs fit all existing fixtures with an E14 and B15 socket. Drawing upon inputs from chandelier makers and designed to enhance the aesthetic appeal of the chandelier or luminaire, not only when lit but also when not, these lamps come in a classical slender shape with a unique, eye-catching lens design. They produce a beautiful sparkling warm light that delivers huge energy savings and minimizes maintenance cost. The flame-shaped candle lamps comes in a classical slender shape with a unique, eye-catching lens design that perfectly complements modern LED candles.

Product data


General Information			
Cap base	E27 [E27]	Luminous efficacy (rated) (nom.)	75 lm/W
Bulb shape	B38	Colour consistency	<6
Nominal lifetime (nom.)	25000 h	Color rendering index (nom.)	80
Switching cycle	50000X	LLMF at end of nominal lifetime (nom.)	70 %
Technical type	6-40W	Operating and Electrical	
		Input frequency	50-60 Hz
		Power (Rated) (Nom)	6 W
		Lamp current (nom.)	35 mA
		Wattage equivalent	40 W
		Starting time (nom.)	0.5 s
		Power factor (nom.)	0.7
Light Technical			
Luminous flux (nom.)	470 lm		
Luminous flux (rated) (nom.)	470 lm		
Colour designation	Warm white (WW)		
Correlated colour temperature (nom.)	2200-2700 K		

MASTER LEDcandle DiamondSpark

Voltage (Nom)	220-240 V
Temperature	
T-Case maximum (nom.)	95 °C
Controls and Dimming	
Dimmable	yes
Mechanical and Housing	
Bulb finish	Clear (CL)
Approval and Application	
Suitable for accent lighting	No
Energy efficiency label (EEL)	A+

Energy Consumption kWh/1000 h	6 kWh
Product Data	
Full product code	871869647479200
Order product name	MASTER LEDcandle DT 6-40W E27 B38 CL
EAN/UPC – product	8718696474792
Order code	47479200
Local Code	MLED6WCANDT27
Numerator – quantity per pack	1
Numerator – packs per outer box	10
Material no. (12NC)	929001157902
Net weight (piece)	0.063 kg

Dimensional drawing

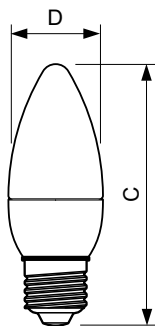

Product	D	C
MASTER LEDcandle DT 6-40W E27 B38 CL	38 mm	112 mm

LED DT 6-40W E27 2200-2700K B38 CL

