



MASTER LEDluster DiamondSpark

MAS LEDlustre DT 8-60W P50 E14 827 CL

Delivering incandescent-like sparkling light effects, MASTER LEDluster bulbs are ideal for general and decorative lighting in the hospitality industry, as well as in home environments. The dimmable MASTER LEDlusters drive further efficiencies, while helping to create the desired atmosphere. Mounted in full view in chandeliers, wall scones or modern luminaires, the clear glass bulb fits all existing fixtures with an E14, E27 and B22 socket. Drawing upon inputs from chandelier makers and designed to enhance the aesthetic appeal of the chandelier or luminaire, not only when lit but also when not, these lamps come in a classical slender shape with a unique, eye-catching lens design. They produce a beautiful sparkling warm light that delivers huge energy savings and minimizes maintenance cost.

Product data

| General Information | |
|--------------------------------------|-----------------|
| Cap base | E14 [E14] |
| Nominal lifetime (nom.) | 25000 h |
| Switching cycle | 50000X |
| Technical type | 8-60W |
| Light Technical | |
| Luminous flux (nom.) | 806 lm |
| Luminous flux (rated) (nom.) | 806 lm |
| Colour designation | Warm white (WW) |
| Correlated colour temperature (nom.) | 2200-2700 K |
| Luminous efficacy (rated) (nom.) | 100.00 lm/W |
| Colour consistency | <6 |
| Color rendering index (nom.) | 80 |


| LLMF at end of nominal lifetime (nom.) | 70 % |
|--|-----------|
| Operating and Electrical | |
| Input frequency | 50-60 Hz |
| Power (Rated) (Nom) | 8 W |
| Lamp current (nom.) | 45 mA |
| Wattage equivalent | 60 W |
| Starting time (nom.) | 0.5 s |
| Warm-up time to 60% light (nom.) | 0.5 s |
| Power factor (nom.) | 0.7 |
| Voltage (Nom) | 220-240 V |

MASTER LEDluster DiamondSpark

| | |
|---------------------------------|------------|
| Temperature | |
| T-Case maximum (nom.) | 95 °C |
| Controls and Dimming | |
| Dimmable | Yes |
| Mechanical and Housing | |
| Bulb finish | Clear (CL) |
| Approval and Application | |
| Energy-saving product | Yes |
| Suitable for accent lighting | No |
| Energy efficiency label (EEL) | A+ |

| | |
|---------------------------------|---------------------------------------|
| Energy Consumption kWh/1000 h | 8 kWh |
| Product Data | |
| Full product code | 871869658067700 |
| Order product name | MAS LEDluster DT 8-60W P50 E14 827 CL |
| EAN/UPC – product | 8718696580677 |
| Order code | 58067700 |
| Numerator – quantity per pack | 1 |
| Numerator – packs per outer box | 10 |
| Material no. (12NC) | 929001211902 |
| Net weight (piece) | 0.084 kg |

Dimensional drawing

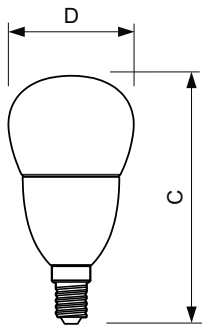

Candle WG EMEA 60W E14 P50

| Product | D | C |
|--|-------|--------|
| MASTER LEDluster DT 8-60W P50 E14 827 CL | 50 mm | 111 mm |

Photometric data

General Uniform Lighting

