

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0511460900

Status:


Active

Overview:

PanelMate™ Wire-to-Board Connector System

Description:

1.25mm Pitch PanelMate™ Wire-to-Board Receptacle Housing, Ultra Low Profile, 9 Circuits

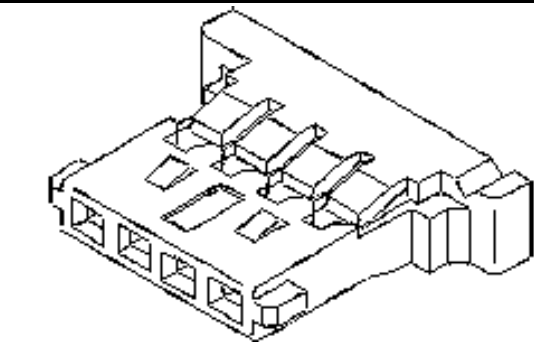

Series image - Reference only

- Documents:
- 3D Model

Product Specification PS-51146-010-001 (PDF)
- Drawing (PDF)

Product Specification PS-51146-012-001 (PDF)
- Product Specification PS-51146-001 (PDF)

Packaging Specification 511469200-200 (PDF)
- Product Specification PS-51146-006-001 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-51146-008-001 (PDF)

Agency Certification	
CSA	LR19980
UL	E107635
General	
Product Family	Crimp Housings
Series	51146
Application	Power, Wire-to-Board
MolexKits	Yes
Overview	PanelMate™ Wire-to-Board Connector System
Product Name	PanelMate™
UPC	800753324305
Physical	
Circuits (maximum)	9
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Net Weight	72.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Temperature Range - Operating	-40°C to +85°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	511469200-200
Product Specification	PS-51146-001, PS-51146-006-001, PS-51146-008-001, PS-51146-010-001, PS-51146-012-001
Sales Drawing	SD-51146-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51146 Series

Mates With

53780

Use With

50641 Crimp Terminal . 50753 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION