

blupont™

SC-1080P-DG-VF-BES CCTV Dome Camera



FEATURES

Image Sensor	1/2.7" OV 2.1MP CMOS Sensor
Resolution	1080P
Signal System	PAL / NTSC
Minimum Illumination	0.01 Lux/F1.2
S/N Ratio	More than 50dB
Synchronous System	Internal
IR Distance	30 Meters (with $\Phi 5 \times 36$ PCS Infrared LED)
IR Power On	Photodiode AUTO Control
Video Output	AHD/CVI/CVBS/TVI
Power/Current	DC12V(+/-10%)/700mA
Lens	2.8-12mm Manual Zoom Lens
Weather Proof	IP 66
Dimension (mm)	$\Phi 131 \times 93$ (H)
Weight (g)	800
Operating Conditions	-10~+50°C RH95% MAX




Day & Night



OSD



IR Cut Filter

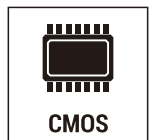

CMOS



IP66



AHD



Auto Gain Control