

blupont™

SC-1080P-DW-BES CCTV Dome Camera



FEATURES

Image Sensor	1/2.7" OV 2.1MP CMOS Sensor
Resolution	1080P
Signal System	PAL / NTSC
Minimum Illumination	0.001 Lux/F1.2
S/N Ratio	More than 50dB
Synchronous System	Internal
IR Distance	20 Meters (with $\Phi 5 \times 42$ PCS Infrared LED)
IR Power On	Photodiode AUTO Control
Video Output	AHD/CVI/CVBS/TVI
Functions	WDR, DNR, UTC
Power/Current	DC12V(+/-10%)/500mA
Lens	Board Len 3.6mm
Weather Proof	IP 65
Dimension (mm)	$\Phi 94 \times 69$ (H)
Weight (g)	400
Operating Conditions	-10~+50°C RH95% MAX




Day & Night



OSD



IR Cut Filter

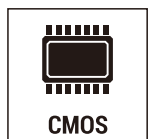

CMOS



IP65



AHD



Auto Gain Control