



Typical Data - See Drawing for Max Data

VNA40-DNFD1-S24


Tr1 S11 Refl SWR RefLvl: 1 U Res: 100 mU/Div

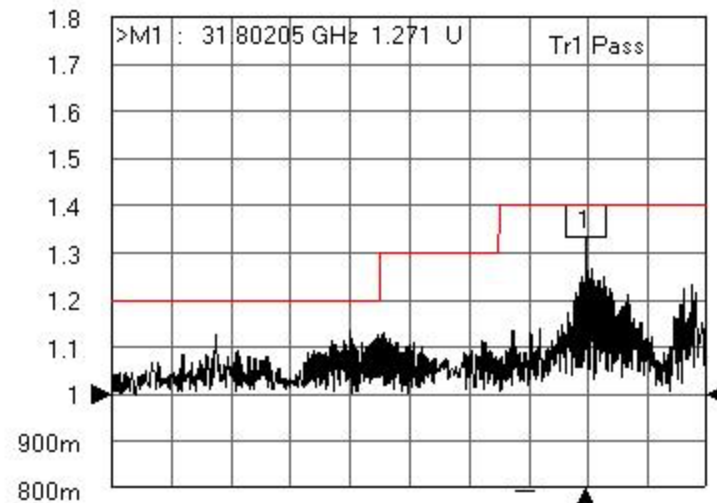

Tr2 S22 Refl SWR RefLvl: 1 U Res: 100 mU/Div

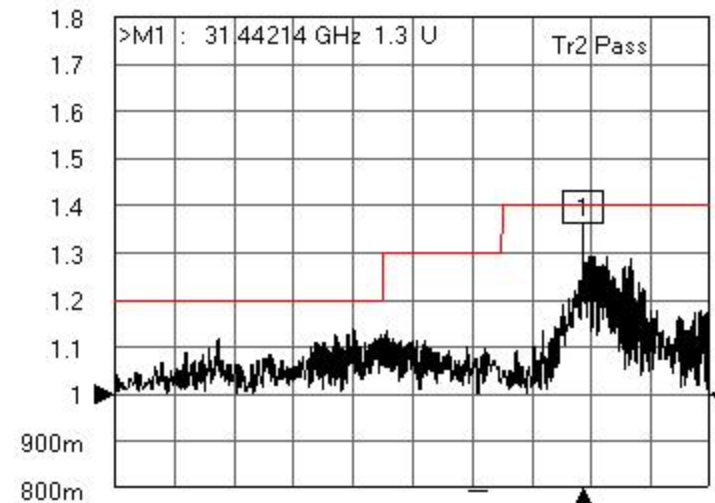

▶ Tr3 S21 Trans LogM RefLvl: 0 dB Res: 1 dB/Div

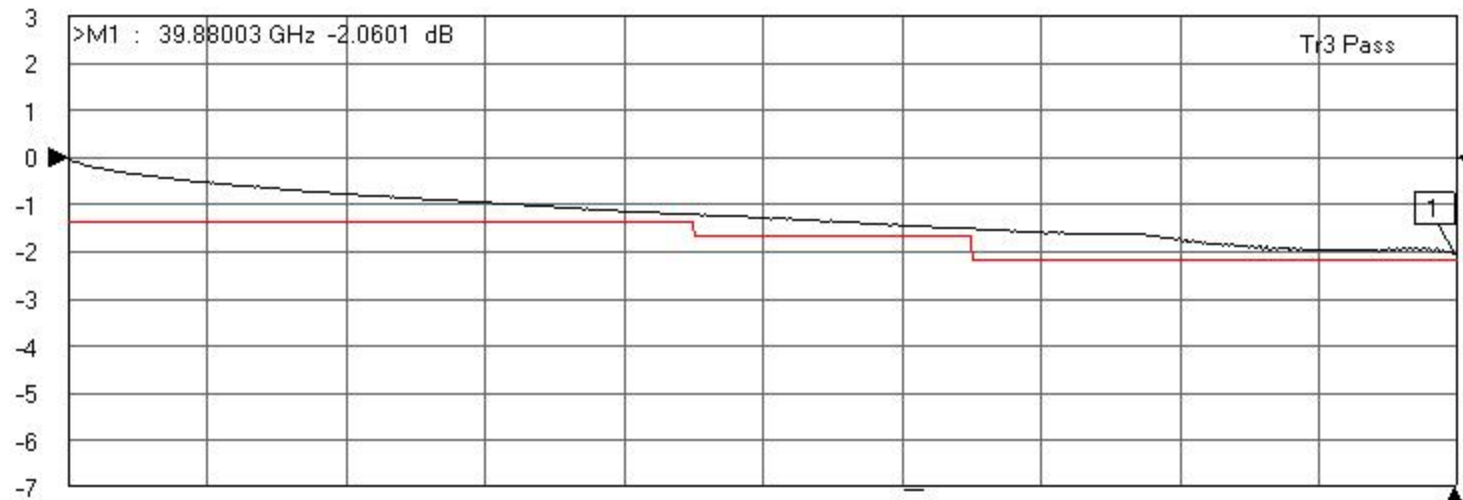

Ch1 TR Start 10 MHz Stop 40 GHz IFBW 3 kHz Avg OFF Measuring State CORR