

SECYOUR™

PLUG 'N' PLAY HOME WIFI CAMERA

SIMPLE HOME MONITORING

View live footage from your iPhone, Android Phone, or PC



Audio



Simple Installation



Message Alerts




Day & Night



IPC011-SEC

Video	
Video compression	H.264, Supports three-stream
Resolution	720P(1280×720@22fps)
Sensor	1/4 inch 720p progressive scan CMOS sensor
Lens/View Angle	3.6mm@F1.2/62.6°
Bit Rate	CBR/VBR, output range:128~4096kbps
Night Vision	Dual IR-Cut filter auto switch, 10pcs LEDs, 10m IR distance
Audio	
Compression format	G711/AAC
Dual-Way-Audio	Support
Network	
Protocol	TCP/IP,HTTP,TCP,UDP,SMTP,FTP,DHCP,DNS,DDNS,NTP,UpnP,RTSP,P2P etc.
Network Function	Supports Gmail/Yahoo Email alarm,FTP,support website update
Online visitor	Supports up to 4 users watching online video simultaneously
WiFi Standard	Supports IEEE 802.11b/g/n
Alarm	
Alert Way	Supports motion detection alarm,Email alert ,upload image to FTP
Software	
Monitor Software	iOS(5.0 or above),Android(2.3 or above),IE,CMS(Windows)
Operation System	Embedded Linux

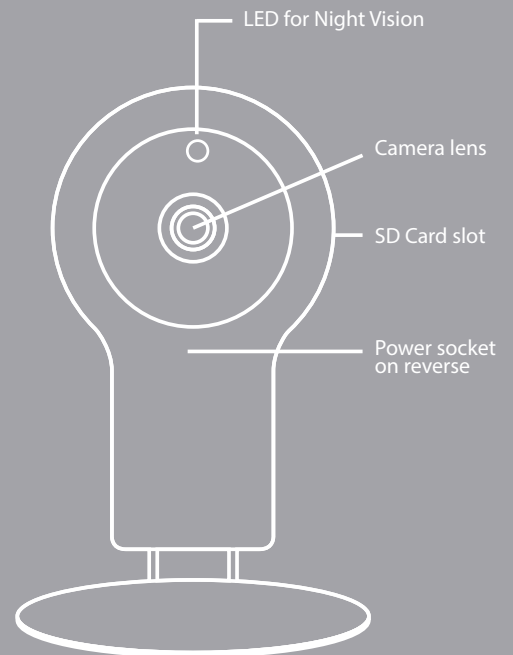

Remote viewing

Connect to your camera over WIFI or 4G, check in on what's important, whenever, wherever*.

Motion Detection

Automatic recording where motion is detected & get email alerts whenever recordings are made.



Night Vision Cameras

Capture footage in total darkness up to a distance of 10m.

High Definition

This Hi-Resolution cameras capture crystal clear 720P images.

* Requires minimum 3G internet connection. Watching on 3G/4G connection will incur data charges