




Made in the United States of America

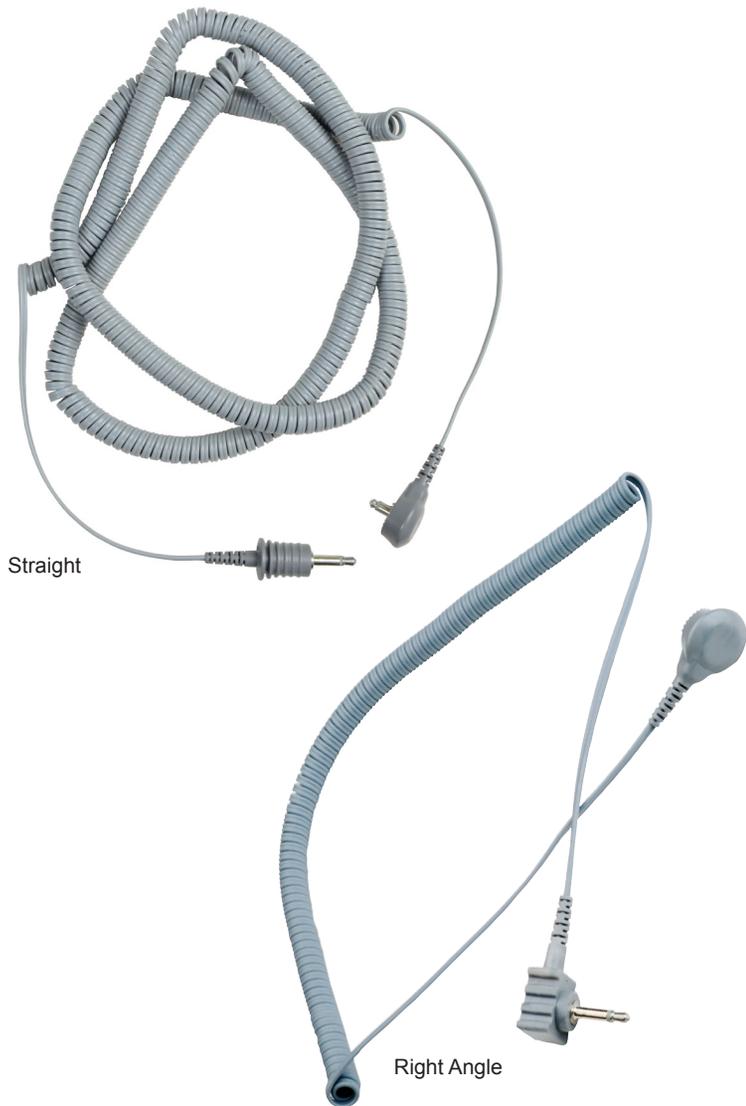

Straight

Right Angle

The 2300 Series Dual Conductor Coil Cord is for use with dual conductor wrist straps and SCS Workstation Monitors. The Dual Conductor Coil Cord features an improved grip that is wider in diameter and easier to grasp when inserting and removing the cord from the remote unit. Having a 1 megohm current limiting resistor (at the end to attach to the wrist band), the Coil Cord meets the resistance requirements of ANSI/ESD S20.20, EIA 625.

Properties	Typical Value
Resistance	One megohm
Flex Life	> 16,000 flexes
Plug Size	3.4mm
Plug Type	Straight or Right Angle
Color	Gray

Item	Description
<a href="#">2360</a>	5ft. (1.5m), Straight
<a href="#">2370</a>	10ft. (30.m), Straight
<a href="#">2371</a>	20ft. (6.1m), Straight
<a href="#">2360R*</a>	5ft. (1.5m), Right Angle
<a href="#">2370R*</a>	10ft. (30.m), Right Angle
<a href="#">2371R*</a>	20ft. (6.1m), Right Angle

\*To be used with SCS Dual Wire Monitors only

Note: This product is not recommended for use on equipment with operating voltage exceeding 250 VAC.

Specifications and procedures subject to change without notice.

### 2300 SERIES - DUAL CONDUCTOR COIL CORD

926 JR Industrial Drive, Sanford, NC 27332  
WEB SITE: [StaticControl.com](http://StaticControl.com)  
PHONE (919) 718-0000

**DRAWING NUMBER**  
2300 Series

**DATE**  
September 2015

