


KEMET Part Number: CA064X223K1RACAUTO



Ceramic, Commercial Grade, CA064, 0.022 uF, 10%, 100 V, 0612, X7R, SMD, MLCC, Array, Flex Termination, Auto Grade

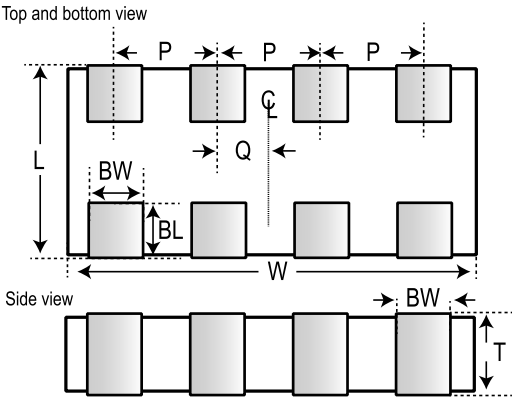

Dimensions

L	1.6mm +/-0.2mm
W	3.2mm +/-0.2mm
T	0.8mm +/-0.1mm
P	0.8mm +/-0.1mm

Packaging Specifications

Packaging:	T&R, 180mm, Plastic Tape
Packaging Quantity:	4000

General Information

Style:	SMD Array
Series:	CA064
Chip Size:	0612
Description:	SMD, MLCC, Array, Flex Termination, Auto Grade
Features:	Automotive
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Approvals:	AEC-Q200
AEC-Q200:	Yes

Specifications

Capacitance:	0.022 uF
Capacitance Tolerance:	10%
Voltage DC:	100 VDC
Temperature Coefficient:	X7R

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

