



DO NOT SCALE  
IF IN DOUBT - ASK


ALL COMPONENTS TO BE ROHS  
COMPLIANT

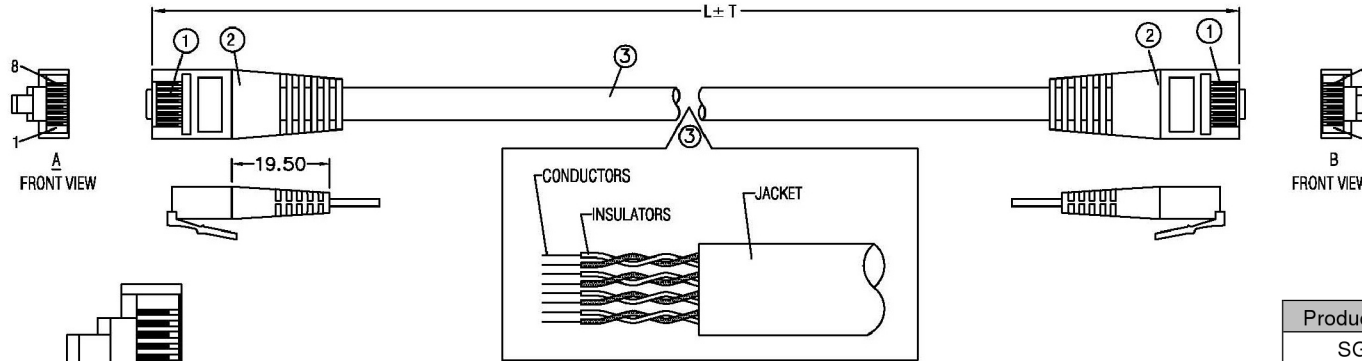

CAT5E FLAT CABLE 32AWG(7/0.08)\*4P(BARE)

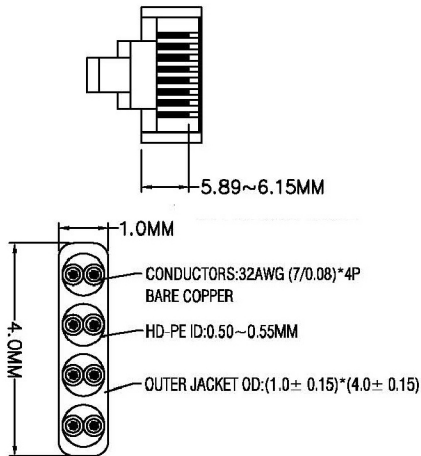

CORD SPECIFICATION

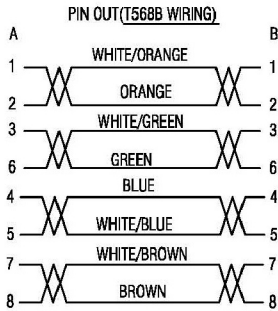

NOTES:

1. ELECTRICAL TEST:100% OPEN,SHORT & MISS WIRE TEST.
2. CONDUCTOR RESISTANCE : 2 OHMS MAX. INSULATOR RESISTANCE: 5M OHMS MIN.
3. HI-POT: DC 300V 0.01sec.
4. ALL MATERIAL FIT ROHS STANDARD(INCLUDE ALL PACKING OR OTHER MATERIAL).
5. PRINTING WORDS OF CABLE: " CAT5E FLAT CABLE RoHS".

NO.	SPECIFICATION STANDARD	QTY
①	RJ45 MALE CONNECTOR,PIN GOLD PLATED Fu <sup>1</sup> .	2
②	50P PVC OUTER MOLDING HOUSING.	2
③	CAT5E FLAT CABLE 32AWG(7/0.08)*4P(BARE COPPER) .	1

Product Name	Product Description
SG426	Cat 5e Slim, Grey, 0.5m
SG427	Cat 5e Slim, Grey, 1m
SG428	Cat 5e Slim, Grey, 2m
SG429	Cat 5e Slim, Grey, 3m
SG430	Cat 5e Slim, Grey, 5m
SG431	Cat 5e Slim, Grey, 10m
SG432	Cat 5e Slim, Grey, 15m
SG433	Cat 5e Slim, Blue, 0.5m
SG434	Cat 5e Slim, Blue, 1m
SG435	Cat 5e Slim, Blue, 2m
SG436	Cat 5e Slim, Blue, 3m
SG437	Cat 5e Slim, Blue, 5m
SG438	Cat 5e Slim, Blue, 10m
SG439	Cat 5e Slim, Blue, 15m
SG440	Cat 5e Slim, Black, 0.5m
SG441	Cat 5e Slim, Black, 1m
SG442	Cat 5e Slim, Black, 2m
SG443	Cat 5e Slim, Black, 3m
SG449	Cat 5e Slim, Black, 5m
SG450	Cat 5e Slim, Black, 10m
SG451	Cat 5e Slim, Black, 15m

REVISION	NOTES	DATE
A		

DRAWN BY	
DATE	
UNITS	METRIC mm

MAT'L:	
TITLE :	Cat5e Assemblies, Slim Type

FINISH:	
PART NO:	As above