

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0760925001

Status:

Active

Overview:

SFP+ and SFP Interconnect Solutions

Description:

Small Form-factor Pluggable Plus (SFP+) Stacked 2-by-4 Multi-Port Connector with 4 Lightpipe Ports, Elastomeric Gasket, 160 Circuits, Tin (Sn) Tails

Documents:

3D Model

Drawing (PDF)

Product Specification PS-75310-001 (PDF)

Application Specification AS-75310-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

I/O Connectors

Series

76092

Application

Module-to-Board

Component Type

Receptacle

Electrical Model

Yes

Overview

SFP+ and SFP Interconnect Solutions

Product Name

SFP Plus

Type

N/A

UPC

800756878034

Physical

Boot Color

N/A

Circuits (Loaded)

160

Circuits (maximum)

160

Circuits Detail

160

Color - Resin

Black, Clear (Blue Tint)

Durability (mating cycles max)

100

Flammability

94V-0

Gender

Female

Keying to Mating Part

None

Lock to Mating Part

Yes

Material - Metal

High Performance Alloy (HPA)

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

High Temperature Thermoplastic, Polycarbonate

Net Weight

97.888/g

Number of Rows

2

Orientation

Right Angle

PC Tail Length

2.07mm

PCB Locator

Yes

PCB Retention

Yes

PCB Thickness - Recommended

1.57mm

Packaging Type

Tray

Panel Mount

No

Pitch - Mating Interface

0.80mm

Pitch - Termination Interface

0.80mm

Plating min - Mating

0.762µm

Plating min - Termination

0.762µm

Polarized to Mating Part


Yes

Polarized to PCB

Yes

Ports

8

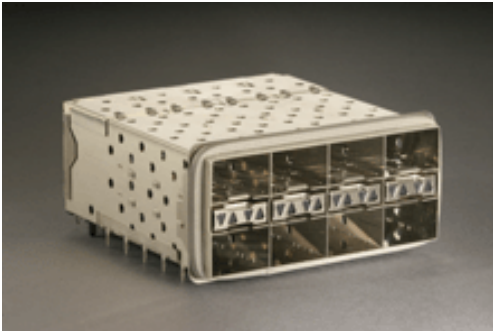

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

76092 Series

Use With

75951-0999 SFP Dust Plug

Application Tooling | [FAQ](#)

Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.

Global

Description	Product #
Stacked Multi-Port Extraction Tool, 2 by 4	0622029940
2-by-4 SFP Stacked Multi-Port Insertion Tool	0622030150

Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Through Hole - Compliant Pin
Waterproof / Dustproof	No
Electrical	
Current - Maximum per Contact	0.5A
Grounding to Panel	None
Shield Type	EMI Gasket
Shielded	Yes
Voltage - Maximum	120V AC (RMS)/DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-75310-001
Electrical Model Document	EE-76090-001
Product Specification	PS-75310-001
S-Parameter Model	SP-76090-001
Sales Drawing	RSD-76046-5900, SD-76092-001

This document was generated on 07/18/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION