

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0468190012

Status:

Active

Overview:

EXTreme Guardian™ System

Description:

EXTreme Guardian™ High Power Terminal, 8 AWG Crimp, 0.76µm Gold (Au)

Documents:

Drawing (PDF)

Product Specification PS-46819-001 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Application

Crimp Quality Equipment

Overview

Product Name

UPC

Crimp Terminals

46819

Power

Yes

EXTreme Guardian™ System

EXTreme Guardian™

883906730949

Physical

Gender

Material - Metal

Material - Plating Mating

Material - Plating Termination

Net Weight

Packaging Type

Plating min - Mating

Plating min - Termination

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Female

Copper

Nickel

Gold

3.590/g

Reel

0.762µm

2.540µm

Crimp or Compression

6.02mm max.

8

N/A

Material Info


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-46819-001

SD-46819-001

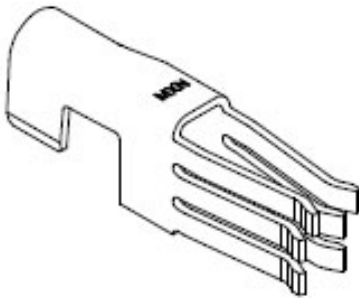

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -ED/79/2015 (17 December 2015)

Halogen-Free

Status

Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

46819 Series

Mates With

46817 Housing

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Mini-Mac™ Applicator Air Feed for Power 60 Amp Crimp Terminals, 8 AWG	0638320700

This document was generated on 03/01/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION