

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1808100001](#)
Status: **Active**
Overview: LED Array Holders, Dual-Ended Wire Trap
Description: LED Array Holder for 23.85 by 23.85mm COB, Round Version 50.00mm Outer Diameter with integrated pre-hold tab and Three-latch bayonet-style reflector attachment, Gold (Au) Plating

Documents:

3D Model	Packaging Specification PK-180810-100 (PDF)
Drawing (PDF)	Test Summary TS-180155-001 (PDF)
Product Specification PS-180810-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-180810-001 (PDF)	

General

Product Family	Solid State Lighting
Series	180810
Array Type	Cree*, Osram†
Beam Angle	N/A
Height	4.10mm
Overview	LED Array Holders, Dual-Ended Wire Trap
Product Name	Wire Trap Holder
Type	LED COB Array Holder
UPC	887191417356

Physical

Base Type	N/A
Color Rendering Index (CRI)	N/A
Correlated Color Temp (CCT)	N/A
Lamp Type	N/A
Mounting Style	Screws
Net Weight	10.177/g
Packaging Type	Tray

Electrical

Lamp Wattage - Maximum	N/A
Lumens	N/A
Voltage (Fixture) - Maximum	300V DC
Wiring Style	Poke In Wire Traps


Material Info

Reference - Drawing Numbers

Application Specification	AS-180810-001
Packaging Specification	PK-180810-100
Product Specification	PS-180810-001
Sales Drawing	SD-180810-001
Test Summary	TS-180155-001

*Cree is a registered trademark of Cree, Inc., *OSRAM is a registered trademark of OSRAM Sylvania, Inc..

†OSRAM is a registered trademark of OSRAM Sylvania, Inc.

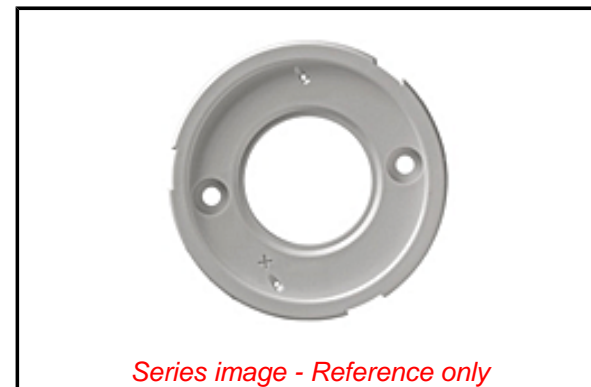

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series
180810 Series