

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050579011

Status:

Active

Overview:

SL™ Modular Connectors

Description:

SL™ Crimp Housing, Single Row, Version A, Non-polarized, 11 Circuits

Documents:

3D Model

Packaging Specification PK-70066-100 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

70066

Application

Signal, Wire-to-Board

Comments

Version A

Overview

SL™ Modular Connectors

Product Name

SL™

UPC

800753629646

Physical

Circuits (maximum)

11

Color - Resin

Black

Flammability

94V-0

Gender

Female

Glow-Wire Compliant

No

Keying to Mating Part

None

Lock to Mating Part

No

Material - Resin

Polyester Alloy

Net Weight

0.078/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

2.54mm

Stackable

Yes

Temperature Range - Operating

-40°C to +105°C

Electrical

Current - Maximum per Contact

3.0A

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Old Part Number

70066-0010


Reference - Drawing Numbers

Packaging Specification

PK-70066-100

Sales Drawing

SD-70066-0001-0024

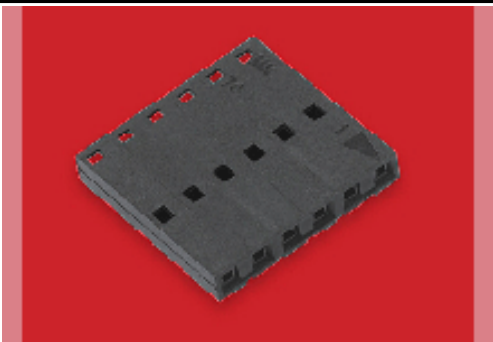

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

70066 Series

Mates With

42375 , 42377 , 70280 , 70287 , 71308 , 70543 , 7 0553

Use With

SL™ Crimp Terminal 70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION