

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5046185010

Status:


Active

Overview:

SlimStack™ 0.35mm pitch Board-to-Board Connectors

Description:

0.35mm Pitch SlimStack™ SSB6 Board-to-Board Receptacle, Surface Mount, Dual Row, Vertical, 0.60mm Stacking Height, 2.00mm Width, 50 Circuits

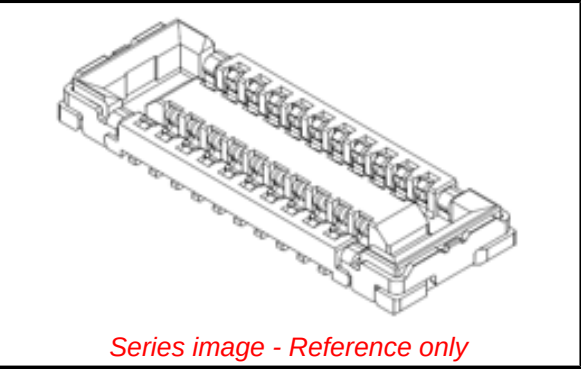

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

General	
Product Family	PCB Receptacles
Series	504618
Application	Board-to-Board
Comments	PCB Retention via Solder Tab
Overview	SlimStack™ 0.35mm pitch Board-to-Board Connectors
Product Name	SlimStack™
UPC	887191511511
Physical	
Circuits (Loaded)	50
Circuits (maximum)	50
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Compliant	No
Mated Height	0.60mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	35.385/mg
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.35mm
Polarized to Mating Part	No
Polarized to PCB	No
Stackable	Yes
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.3A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-504618-001, SD-504618-002

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

China RoHS

Green Image

Not Relevant

Search Parts in this Series

504618 Series

Mates With

504622 0.35mm Pitch Sl...

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION