

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5046225010](#)
Status: **Active**
Overview: SlimStack™ 0.35mm pitch Board-to-Board Connectors
Description: 0.35mm Pitch SlimStack™ SSB6 Board-to-Board Plug Connector, Surface Mount, Dual Row, Vertical, 0.60mm Stacking Height, 2.00mm Width, 50 Circuits


Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General	
Product Family	PCB Headers
Series	504622
Application	Board-to-Board
Overview	SlimStack™ 0.35mm pitch Board-to-Board Connectors
Product Name	SlimStack™
UPC	887191511627
Physical	
Breakaway	No
Circuits (Loaded)	50
Circuits (maximum)	50
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Compliant	No
Mated Height	0.60mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	18.800/mg
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.35mm
Polarized to Mating Part	No
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers
Sales Drawing SD-504622-001, SD-504622-002

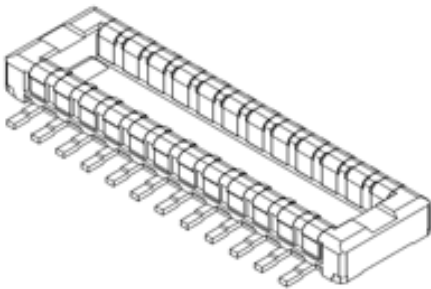

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series

[504622](#) Series

Mates With

[504618](#) 0.35mm Pitch SlimStack™ SSB6
Board-to-Board Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION