

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5020782510](#)
Status: **Active**
Overview: FFC-FPC (SMT)
Description: 0.25mm Pitch Easy-On™ Type FPC Connector, 1.00mm Mated Height, Right Angle, Surface Mount, Bottom Contact Style, 25 Circuits, Halogen-Free

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	FFC/FPC Connectors
Series	502078
Overview	FFC-FPC (SMT)
Product Name	Easy-On™
UPC	883906193614

Physical

Circuits (Loaded)	25
Contact Position	Bottom
Durability (mating cycles max)	10
Entry Angle	90° Angle
Mated Height	1.00mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	38.526/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.25mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-20°C to +85°C
Termination Interface: Style	Surface Mount
Wire/Cable Type	FPC only


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V

Material Info

Reference - Drawing Numbers

Sales Drawing SD-502078-003, SD-502078-004

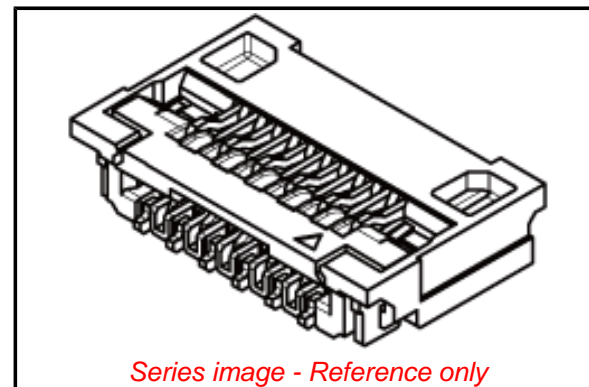

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

[502078 Series](#)