

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5023510800](#)
Status: **Active**
Overview: [DuraClik™ Connector System](#)
Description: [DuraClik™ Wire-to-Board Receptacle Housing, Single Row, 8 Circuits, Natural](#)

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Crimp Housings
Series	502351
Application	Signal, Wire-to-Board
Comments	Molex part has an inner-locking system versus an outer-locking system. Molex part with tail protection feature.
Overview	DuraClik™ Connector System
Product Name	DuraClik™
UPC	800756666877

Physical

Circuits (maximum)	8
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Net Weight	328.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact	3.0A
-------------------------------	------


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Product Specification	RPS-502351-010-JP
Sales Drawing	SD-502351-001

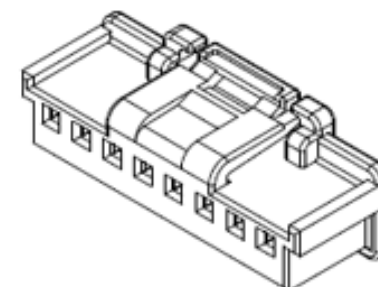

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS
ELV

China RoHS

Green Image
Compliant

Search Parts in this Series

[502351](#) Series

Mates With

[560020](#) , [502352](#) 2.00mm Pitch DuraClik™ Wire-to-Board Header

Use With

[560085](#) DuraClik™ Crimp Terminal AWG 22-26, [50212](#) 2.00mm Pitch Crimp Terminal AWG 24-30, [56161](#) 2.00mm Pitch Crimp Terminal AWG 22-26