

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5035480620

Status:

Active

Overview:

SlimStack™ 0.40mm Pitch Board-to-Board Connectors

Description:

0.40mm SlimStack™ Board-to-Board Receptacle, Surface Mount, Dual Row, Vertical, 0.70mm Stacking Height, Hi-Retention Type, 6 Circuits

Documents:

3D Model

Drawing (PDF)


RoHS Certificate of Compliance (PDF)

General	
Product Family	PCB Receptacles
Series	503548
Application	Board-to-Board
Overview	SlimStack™ 0.40mm Pitch Board-to-Board Connectors
Product Name	SlimStack™
UPC	884982249790
Physical	
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Mated Height	0.70mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	8.510/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Polarized to Mating Part	No
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Surface Mount

Electrical	
Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC/DC

Material Info

Reference - Drawing Numbers	
Sales Drawing	SD-503548-005, SD-503548-006

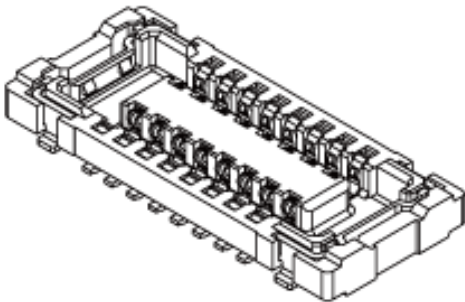

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/21/2016 (20 June

2016)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

503548 Series

Mates With

503552 SlimStack™ PCB Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION