

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0397000904](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 5.00mm Pitch, Eurostyle™ Fixed-Mount Push-Button Terminal Block, Vertical, 10A, 22-14 AWG, Green, 4 Circuits

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Terminal Blocks
Series [39700](#)
Application Wire-to-Board
Component Type Push-Button
Overview [Eurostyle™ Terminal Blocks](#)
Product Name ESE, Eurostyle™ Fixed Mount
Type Euro Block
UPC 78172542642

Physical
Circuits (Loaded) 4
Circuits (maximum) 4
Color - Resin Green
Entry Angle Vertical
Lock to Mating Part No
Material - Plating Termination Tin
Material - Resin Nylon
Number of Rows 1
Orientation Vertical
Panel Mount Yes
Pitch - Mating Interface 5.00mm
Polarized to Mating Part No
Stackable No
Temperature Range - Operating -40°C to +105°C
Wire Size AWG 14, 16, 18, 20, 22

Electrical
Current - Maximum per Contact 10.0A
Voltage - Maximum 300V

Material Info
Old Part Number M851-01-1-04-3

Reference - Drawing Numbers
Sales Drawing SD-39700-010

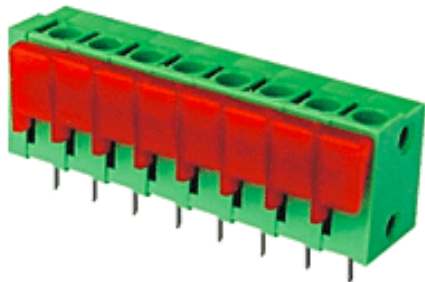

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/108/2014 (17 Dec
2014)
Halogen-Free
Status
Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
[39700 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION