

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0430610008

Status:


Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

3.96mm Pitch SPOX™ Housing, 8 Circuits

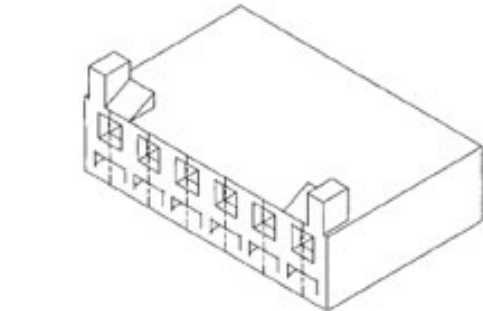

Series image - Reference only

Documents:

3D Model

Packaging Specification PK-43061-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	43061
Application	Power, Wire-to-Board
Comments	Glow Wire Equivalent Part Number 43061-3008
Overview	SPOX™ Wire-to-Board Connectors
Product Name	SPOX™
UPC	800753576414
Physical	
Breakaway	No
Circuits (maximum)	8
Circuits Detail	8
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	2.637/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Pitch - Termination Interface	3.96mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	0°C to +75°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-43061-001
Sales Drawing	SD-43061

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/79/2015 (17

December 2015)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

43061 Series

Mates With

3.96mm Pitch KK® or SPOX® headers

Use With

SPOX™ Terminal 5194 , 5225

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION