

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0847330004**
Status: **Active**
Overview: Sealed Industrial USB Solutions
Description: Sealed Industrial USB 3.0 TYPE A Receptacle-to-Sealed Industrial USB Type A Plug Double-Ended Cord Set, .810m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-84733-001 \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	84733
Assembly Configuration	Dual Ended Connectors
Comments	Fully shielded for EMI/RFI protection
Connector to Connector	Type A Recept-to-Type A Plug
Overview	<u>Sealed Industrial USB Solutions</u>
Product Name	Industrial USB
UPC	887191633206

Physical

Cable Length	0.81m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Dual
Material - Resin	PVC
Packaging Type	Bag
Single Ended	No
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP67, NEMA 6P
Wire Size AWG	N/A
Wire/Cable Type	USB


Electrical

Current - Maximum per Contact	1.0A
Impedance	Non-constant
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V AC (RMS)

Material Info

Reference - Drawing Numbers

Product Specification	PS-84733-001
Sales Drawing	SD-84733-001

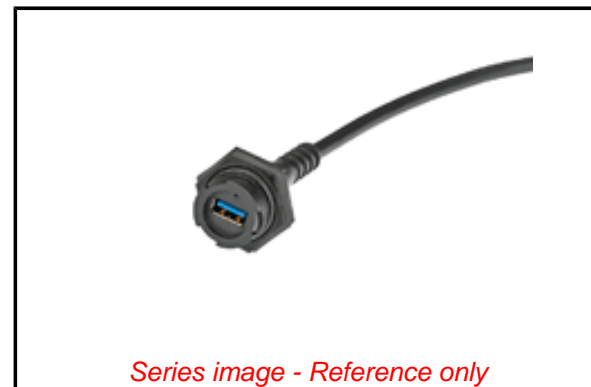

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
ED/108/2014 (17 Dec
2014)

Dibutylphthalate

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

84733 Series