

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1302990100](#)
Status: **Active**
Overview: Brad® Micro-Change® (M12) Connectors
Description: Brad® Micro-Change® (M12) Harsh-Duty Receptacle, 4 Pole, D-Code, Right Angle

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-130299-001 \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	130299
IP Rating	IP67
Overview	Brad® Micro-Change® (M12) Connectors
Product Name	Micro-Change® (M12)
Type	PCB Mount
UPC	78172513052

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	D-coded
Length	N/A
Material - Component	Nickel-plated Zinc Die-Cast
Mounting Thread Size	M12 x 1.0
Orientation	90° Angle
Panel Mount	Back, Front
Poles	4
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	N/A
Wire/Cable Type	N/A


Electrical

Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-130299-001
Sales Drawing	SD-130299-005

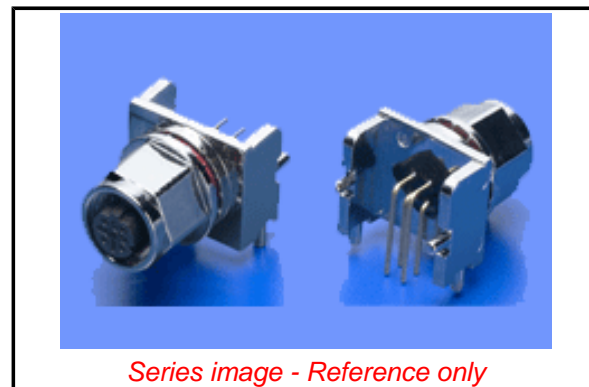

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/108/2014 (17 Dec 2014)

Dibutyl phthalate (DBP)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

Search Parts in this Series

[130299](#) Series

Mates With

Male D-Code Cable Assembly