


Magnetic Alarm Reed Switch

Features

- Mini Stick-On Contact with Flange Center Leads
- 18" Leads
- Adhesive and Screw Mount
- Standard Gap: 1" (25mm)



S107

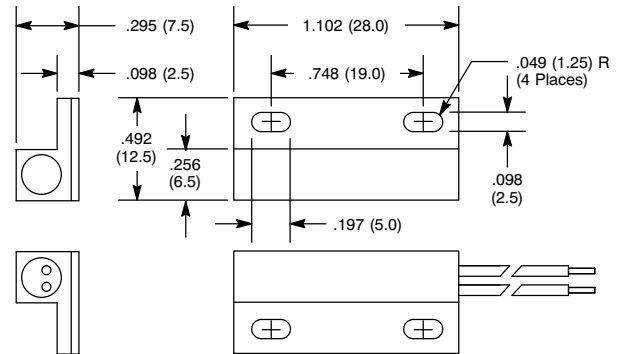

Specifications

- Contact Rating:** 10W/VA
- Contact Resistance:** 150 milliohms.
- Contact Material:** Ruthenium Oxide over Palladium
- Switching Voltage:** 200 VDC max.
- Switching Current:** 500mA max.
- Insulation Resistance:** 10 gigohms
- Shock Resistance:** 30G for 11mS
- Vibration Resistance:** 20G (10 to 1000Hz)
- Life Expectancy:** 20,000,000 cycles (resistive load, 12VDC, 250mA)
- Terminal Type:** Wire Leads
- Mounting Hole:** .200" (5mm)

NTE Type No.	Color	Circuitry	Action	Actuator	Diag No.
54-630	White	SPST-NO	NO for Closed Loop System	Magnet	S107
54-636	Brown	SPST-NO	NO for Closed Loop System	Magnet	S107